



M8 3-pol an/st m/f PUR



Technische Daten:

Bemessungsspannung: IEC 61076-2-101	60 V
Strombelastbarkeit: IEC 61076-2-101	3 A / 40°C
Isolationswiderstand: IEC 60512	>=100 MΩ
Verschmutzungsgrad: IEC 60664-1	3/2
Schutzart: IEC 60529	IP 67, im verschraubten Zustand
Umgebungstemperatur: EN 60512-11-10 EN 60512-11-4	-25°C ... +80°C -40°C -40°C ... +85°C
Steckzyklen: IEC 60512-9a	>=100

Kabeleigenschaften:

Umgebungstemperatur:	
fest verlegt	-30°C ... +80°C
bewegt	-5°C ... +80°C
Kabel:	PUR, UL 20549, schwarz 3x0,25mm ² , 3Li 9Y


Werkstoffe:

Kontakt:	CuZn, Ni b / Au 0,2 gal.
Kontaktträger:	TPU, UL 94
Dichtung:	FPM
Überwurfmutter/-schraube:	GD-Zn, Ni
Griffkörper:	TPU, UL 94 HB, schwarz



Montagedaten:

empfohlenes Drehmoment:	0,4 Nm
-------------------------	--------

male

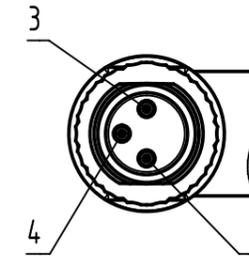

female

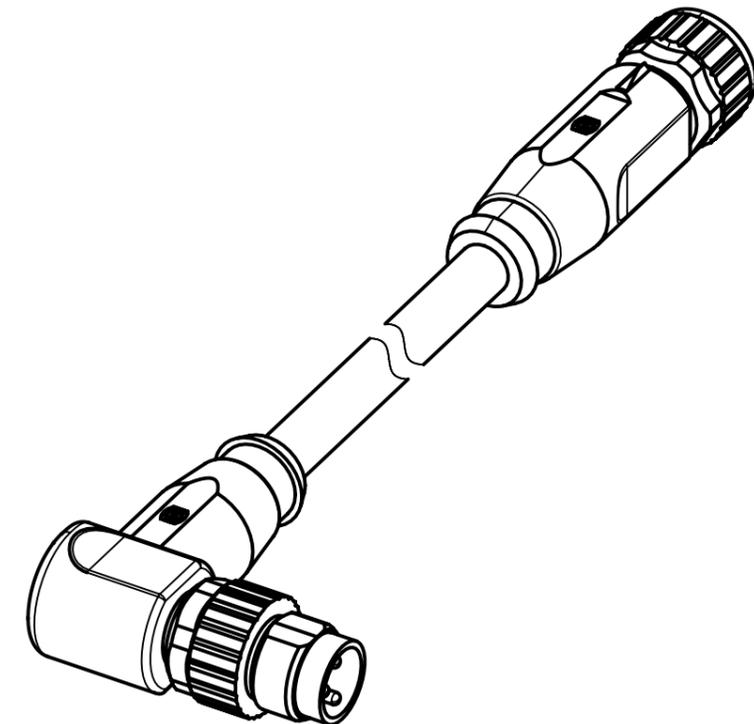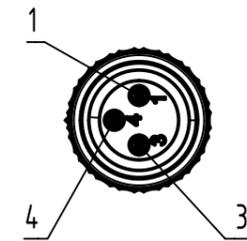

	All Dimensions in mm	Tech. Character.	Free size tol.	According to production drawing
--	----------------------	------------------	----------------	---------------------------------

	All rights reserved	Created by 405170 Huzu	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2021-03-24	State Final Release	Doc-Key / ECM-Nr. 100944730/UGD/000/B 500000191803
	Department HCS - RO	Title M8 3-pol an/st m/f PUR		Rev. B		Page 1/2	
HARTING Customised Solutions D-32339 Espelkamp		Type DS	Number 21348281388XXX				



M8 3-pol an/st m/f PUR



Technical specifications:

Operating voltage: IEC 61076-2-101	60 V
Rated current: IEC 61076-2-101	3 A / 40°C
Insulation resistance: IEC 60512	>=100 MΩ
Degree of pollution: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, im mated status
Temperature: EN 60512-11-10 EN 60512-11-4	-25°C ... +80°C -40°C -40°C ... +85°C
Mating cycles: IEC 60512-9a	>=100

Cable specifications:

Temperature:	
Temperature range fixed cable	-30°C ... +80°C
Temperature range moveable cable	-5°C ... +80°C
Cable:	PUR, UL 20549, black 3x0,25mm ² , 3Li 9Y


Materials:

Contact:	CuZn, Ni b / Au 0,2 gal.
Contact carrier :	TPU, UL 94
Seal:	FPM
Screw:	GD-Zn, Ni
Overmolding:	TPU, UL 94 HB, black



Assembly:

Torque:	0,4 Nm
---------	--------

male

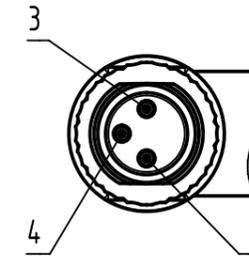

female

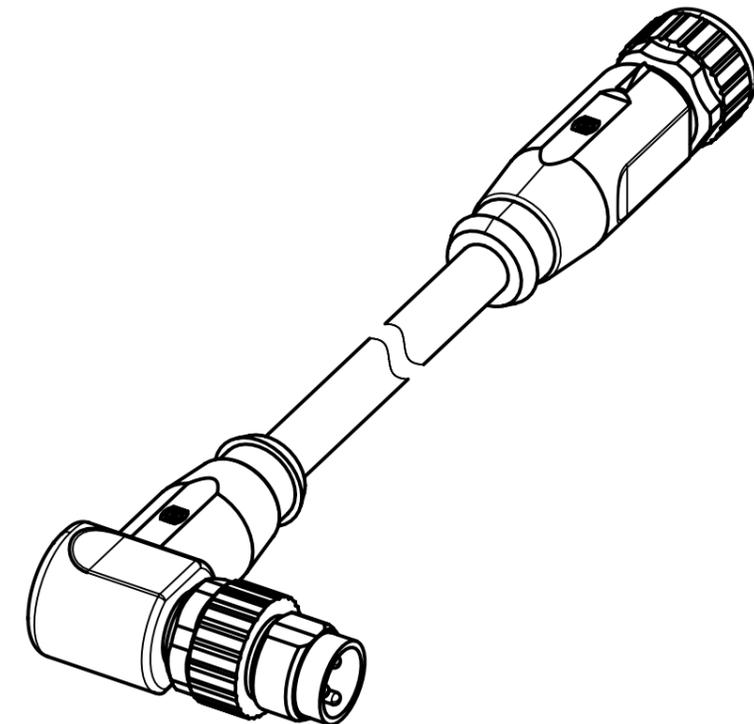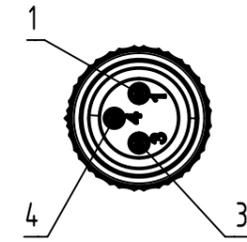

	All Dimensions in mm	Tech. Character.	Free size tol.	According to production drawing
--	----------------------	------------------	----------------	---------------------------------

	All rights reserved	Created by 405170 Huzu	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2021-03-24	State Final Release	Doc-Key / ECM-Nr. 100944730/UGD/000/B 500000191803
	Department HCS - RO	Title M8 3-pol an/st m/f PUR		Rev. B		Page 2/2	
HARTING Customised Solutions D-32339 Espelkamp		Type DS	Number 21348281388XXX				