




Brand-Rex Copper Connectivity - Cat6Plus Panels
 Category 6 Panel with cable management

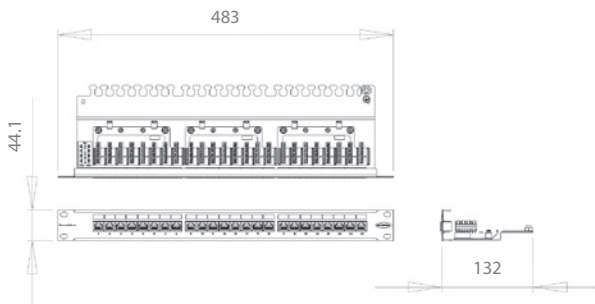

PRODUCT DESCRIPTION

The Cat6Plus 19" rack mounted patch panel offers true Category 6 component performance using a new patented contact pin array design. All panels are backward compatible. The modular jacks that are used in blocks of 8 are individually shielded to give superior shielding.

In addition to this, each panel has been designed with a cable management/strain relief feature built into the rear. All outlets are numerically identified with an additional writable surface for ease of port naming. Each panel is supplied with cable ties, panel mounting accessories and short form installation instructions.

PRODUCT CHARACTERISTICS

- Panel Width: 19" (483mm)
- Panel Height: 1U (44.1mm)
- Panel Depth: 132mm
- Outlet Style: Unkeyed RJ-45
- Outlets: 24 ports
- Colour: RAL 9005 Black or RAL 7035 Grey
- Punch Down Blocks: LSA style IDC
- Wiring Standard: EIA/TIA 568A/B
- Conformance: Category 6
 ANSI/EIA/TIA 568B C SERIES
 ISO/IEC 11801
 AMMENDMENTS
 EN50173-1

Product Part Numbering

	24 Port
Shielded Panel LSA Style - Black	C6CPNLF240K2M
Shielded Panel LSA Style - Grey	C6CPNLF240K8M
Unshielded Panel LSA Style - Black	C6CPNLU240K2M
Unshielded Panel 110 Style - Black	C6CPNLU24012M