

## Features


- The magnets are protected in steel cups, which greatly increases the life of the magnets
- Can be screwed into the wall or ceiling with an appropriate countersunk screw
- Maximum operating temperature of 200 °C
- Ideal magnet assembly for consumer & industrial applications which require medium magnetic strength, such as lifting, antenna or light mounts, latches, furniture & home repair projects, closing mechanisms, retrieving objects & more



## Material

Housing steel and ferrite countersink magnet

## Specification

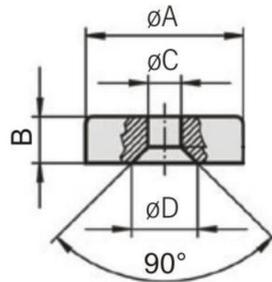

Model	A (mm)	B (mm)	C (mm)	D (mm)	Weight (g)	Pull Force (kg)
RND 610-00901	20	6.0	4.2	9.0	9	2.2
RND 610-00902	32	7.0	5.5	11	27	5.9
RND 610-00903	50	10	8.5	22	85	18.3