

ToLEDo Platinum RT Candle 485LM 827 E14 SL


Item No: 0030140



Ultra-efficient LED filament lamp range with the same reminiscent look of the classic traditional lamp Save up to 95% on energy bills compared to old incandescent lamps Energy Class A and best-in-class lumen efficacy Sustainable and eco-friendly solution Last three times longer than the standard LED retrofit lamps Remarkable 50,000 hours average rated life – reducing the hassle of frequent replacements Sparkling light effect Ideal for everyday lighting in homes, hotels, restaurants and more Omni-directional light distribution Non-dimmable

Technical Assets

Dimensions (mm)

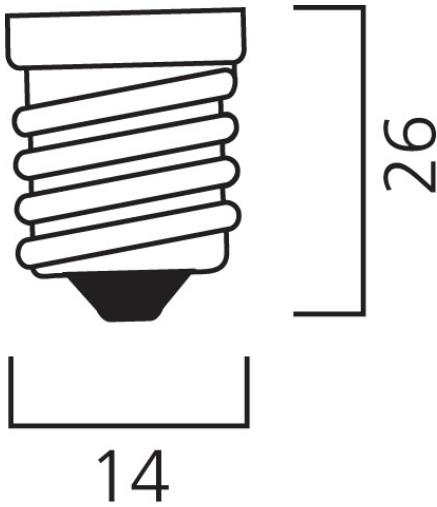

Photometrics

ToLEDo Platinum RT Candle 485LM 827 E14 SL

Item No: 0030140

SYLVANIA

General data

Product name	ToLEDo Platinum RT Candle 485LM 827 E14 SL
Technology	LED
Lamp shape	Candle
Cap/Base	E14
Lamp finish	Clear
Fixture rating	Open
General application	Hospitality, Residential & Consumer
Operating temperature range (°C)	-20°C...+40°C
ETIM Class	EC001959
E-number FI	4741179
Warranty	5 years

Optical data

Useful luminous flux (Φuse)	485
Correlated colour temperature (k)	2700
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	320
Photobiological Risk Group	RG1

Electrical data

Power consumption (W)	2.2
Wattage (W)	2.3
Equivalent watt (W)	40
Current (A)	0.021
Primary Supply/Product voltage - min (V)	220.0
Primary Supply/Product voltage - max (V)	240.0
Control gear required	No
Control gear type	LED driver constant current
No. Of switching cycles before premature failures	>50000
Dimmable	No
Dimming method	N/A
Inrush Current (A)	9
Inrush Duration (µs)	130
Lamp Energy Label (class)	A
Nominal Frequency (Hz)	50/60Hz

Lifetime data

Lifespan L70 B50	50000
------------------	-------

Physical data

Housing colour	Transparent
IP rating	IP20
Nominal Product Height (mm)	97
Nominal Product Diameter (mm)	35
Weight (kg)	0.025

ToLEDo Platinum RT Candle 485LM 827 E14 SL

Item No: 0030140



Packaging

Product EAN number	5410288301402
Packaging single length / height (cm)	4.5
Packaging single width (cm)	4.5
Packaging single depth (cm)	11.0
DUN14 (inner)	15410288301409
Units per outer package	6
Packaging outer length / height (cm)	14.3
Packaging outer width (cm)	9.7
Packaging outer depth (cm)	12.0

Safety data

Optimal operating condition (°C)	-20-40
Breakage cleaning instructions	Not applicable
Special purpose lamp	No
Dry applications use only	Yes
Suitable for household illumination	Yes
Safety message	Not Suitable for totally enclosed fixtures