


Part Number: 1904X25X

Type	Size	Rating	Description
LED	M8	12Vdc	LED Prominent Panel Indicator

Dimensions (mm)

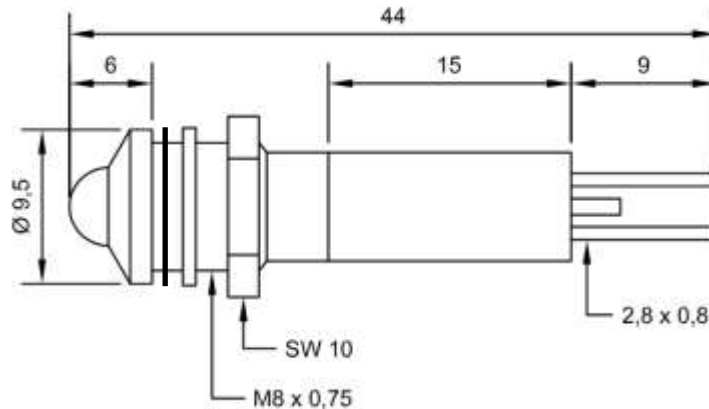

Part #	Colour	Current (mA)	Intensity (mcd)
1904X250	Red	25	12
1904X251	Green	25	50
1904X252	Yellow	25	50
1904X253	HE-Red	25	60
1904X257	Blue	20	90
1904X25W	White	7	800

Bezel types - X=0 satin chrome / X=1 black chrome / X=2 matt chrome

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Luminous intensity at DC
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 Sealed to IP67 above panel when supplied gasket used
- 7 The plastic(polycarbonate) has limited chemical resistance
- 8 RoHS & REACH SVHC compliant