



Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 521206-8  
POSI-LOK HSG.250-4 POS RAST5



TE Part # 2390868-4  
4P, RAST 5 HEADER, PL, SHROUDED

Customers Also Bought



TE Part #2238136-2  
RECEPTACLE, POSITIVE-LOCK, RAST 6.35



TE Part #521204-2  
HSG RCPT POSI MK 111 250 2POS



TE Part #794221-1  
MINI UMN2 SOK 22-18 AWG SN




TE Part #173722-1  
187 PL EX REC. 26-20AWG TPBR



TE Part #520963-1  
ULTRA-POD 250 ASSY REC 18-14 AWG BR



TE Part #63476-2  
187 FASTON FLAG REC 20-16 AWG TPBR

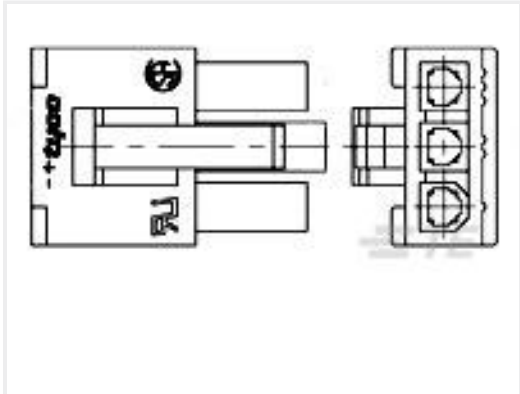

TE Part #1586106-3  
3P RCPT VAL-U-LOK SR V0



TE Part #170011-2  
RING STRIP 18-14 MM2 0.503 X 11.938 TPBR



TE Part #42864-1  
RING CRIMP 12-10 AWG BR



TE Part #520973-1  
ULTRA-POD 187 ASSY REC 20-16 AWG BR

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_521206-7\_R.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_521206-7\_R.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_521206-7\_R.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

RAST Connector System Catalog

English

Product Specifications



Engineering Report

English