


Features

- Allows 180° free movement
- Ideal for control panels and enclosures requiring robust, non-self-closing hinges

RS PRO Hinges

RS Stock No.: 0726448

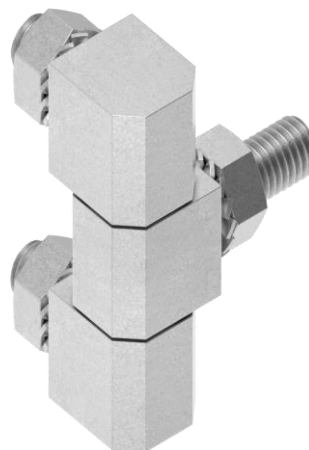

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

This is a zinc-plated steel hinge designed for surface mounting on industrial cabinets. It allows 180° free movement, features a captive pin, and is suitable for visible door applications. Ideal for control panels and enclosures requiring robust, non-self-closing hinges.

General Specifications

Material	Steel (zinc-plated)
Hinges Type	Visible hinge
Closing Type	Free movement
Fixing Method	Bolts
Pin Style	Fixed
Finish	Zinc-plated
Handed	Left; Right
Colour	Metallic
Applications	For residential and commercial folding windows

Mechanical Specifications

Length	49mm
Width	18mm
Thickness	16mm
Fixing Hole Sizes	8.0mm
Radial Load	3500 N
Axial Load	3500 N
Recommended Tightening Torque	5 Nm
Weight	135g
Pin Diameter	8mm
Opening Angle	180°
Screw Gauge	M8 screws
Fixing Centres	33mm