


932HS
**double ended hexagon / bi-hex offset socket wrenches, bright chrome-plated
 H-SAFE**
NF E 74.303

with H-SAFE tethered system

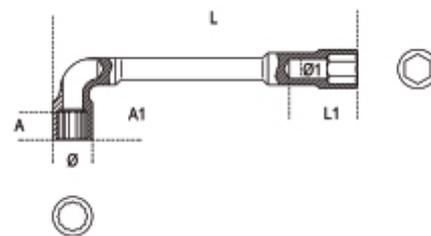

art.	mm	Ø mm	L mm	Ø1 mm	A mm	A1 mm	L1 mm	g
009324006	6x6	11,5	110	5,0	8,0	15,0	15,0	55
009324007	7x7	12,5	116	6,0	9,0	18,0	15,0	60
009324008	8x8	13,0	120	6,0	11,0	20,0	21,0	65
009324009	9x9	14,0	125	7,0	11,0	20,0	21,0	75
009324010	10x10	16,5	133	8,0	13,0	22,0	25,0	105
009324011	11x11	17,5	143	8,5	14,0	23,0	25,0	125
009324012	12x12	19,0	148	8,5	14,0	25,0	25,0	165
009324013	13x13	19,5	154	9,5	16,0	28,0	34,0	175
009324014	14x14	21,5	167	10,0	17,0	28,0	34,0	220
009324015	15x15	22,5	182	10,0	17,0	29,0	40,0	235
009324016	16x16	24,5	193	11,0	20,0	33,0	40,0	335
009324017	17x17	26,0	198	12,0	20,0	34,0	44,0	340
009324018	18x18	26,5	215	13,0	20,0	34,0	44,0	370
009324019	19x19	29,0	220	14,0	22,0	35,0	48,0	435