



Ratchet wrenches


For our ratchet wrench range, see
section 4, page 136



Fast series




TWICE AS FAST

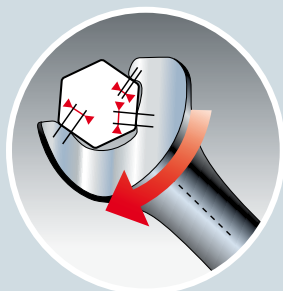


40R - Ratchet-effect combination wrench

Ratchet effect.

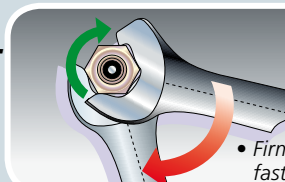

- Firm pressure on fastener flats.

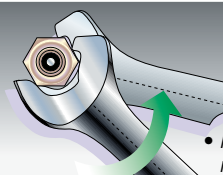


- Rewind action without removing the tool.

3 drive surfaces.

- Less wear.
- Less risk of tool slippage.

Easier positioning and withdrawal.

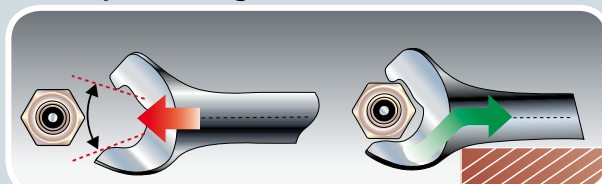

40R Metric fast combination wrenches

▷ ISO 7738, DIN 3113, NF ISO 7738.

- Metric sizes 8 to 24 mm.
- 12-point OGV® ring angled at 15°.
- Satin chrome finish.

40R	A mm	B x B' mm	C x C' mm	L mm	ΔΔ g
40R.8	8	18,5 x 12,9	4,3 x 6	126	26
40R.9	9	20,5 x 14	4,3 x 6,1	133	29
40R.10	10	22,9 x 15,9	4,8 x 6,6	141	39
40R.11	11	24,9 x 17	5,1 x 7	148	45
40R.12	12	26,8 x 18,4	5,3 x 7,5	157	56
40R.13	13	28,8 x 19,8	5,6 x 8	165	61
40R.14	14	30,6 x 21,2	6 x 8,5	172	73
40R.15	15	32 x 22,4	6,6 x 9,2	179	79
40R.16	16	34,8 x 23,8	6,9 x 9,8	187	93
40R.17	17	36,7 x 25	7 x 10,3	193	113
40R.18	18	38,5 x 26,4	7,4 x 10,9	201	120
40R.19	19	40,9 x 29,4	7,6 x 11,3	209	140
40R.20	20	42,5 x 29,4	8 x 11,6	217	165
40R.21	21	45 x 30,7	8,1 x 11,9	223	182
40R.22	22	47 x 32	8,2 x 12,3	240	205
40R.23	23	48,5 x 33,4	8,4 x 12,6	250	236
40R.24	24	50,5 x 34,7	8,5 x 12,9	260	260

