




HYDNUT365-E [🔗](#)

Hydraulic nut

HYDNUT...-E

Technical information

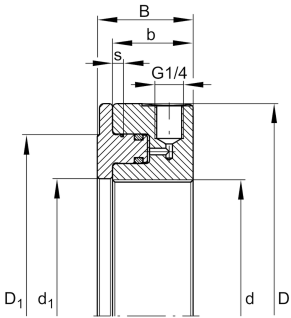

Your current product variant

Series	E	metric fine pitch thread/trapezoid thread
--------	---	---

Technical data

d	Tr365x5	Thread
D	482 mm	Outer Diameter
B	65 mm	Width
b	54 mm	Width press ring
D 1	436 mm	
d 1	367 mm	
s	15 mm	Stroke, max.
	316.7 cm²	Piston surface
	500 bar	Pressure, max.
	1,584 kN	Drive-up force, max.
≈m	40.1 kg	Weight

Additional information

1 pc. Hydraulic nut, 3 pcs. Clamping screws, 1 pc. Screw plug, 1 pc. Connection nipple, 3 pcs. to 5 pcs. Threaded pins, 1 pc. Hand lever, 1 pc. Replacement seal set, 1 pc. User manual	Delivery scope
--	----------------