


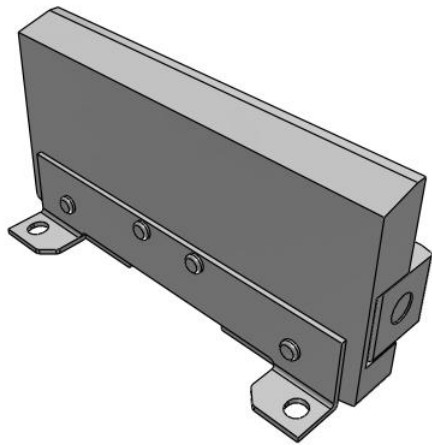

EX245-EA2, End Plate EX245-EA2-1

Datasheet


General series information

- Available with bracket.

Standard specifications

Bracket	1 (w/Bracket)
Operating humidity range	Operating, Stored: 35 to 85 % RH (No condensation)
Enclosure	IP65 (Manifold assembly, With seal cap)
Operating temperature range	Operating: -10 to 50 °C, Stored: -20 to 60 °C (No condensation)
Withstand voltage	500 VAC for 1 minute between external terminals and FE
Insulation resistance	500 VDC, 10 MΩ or more between external terminals and FE
Standards	CE
Weight	0.200 Kg

Dimensions

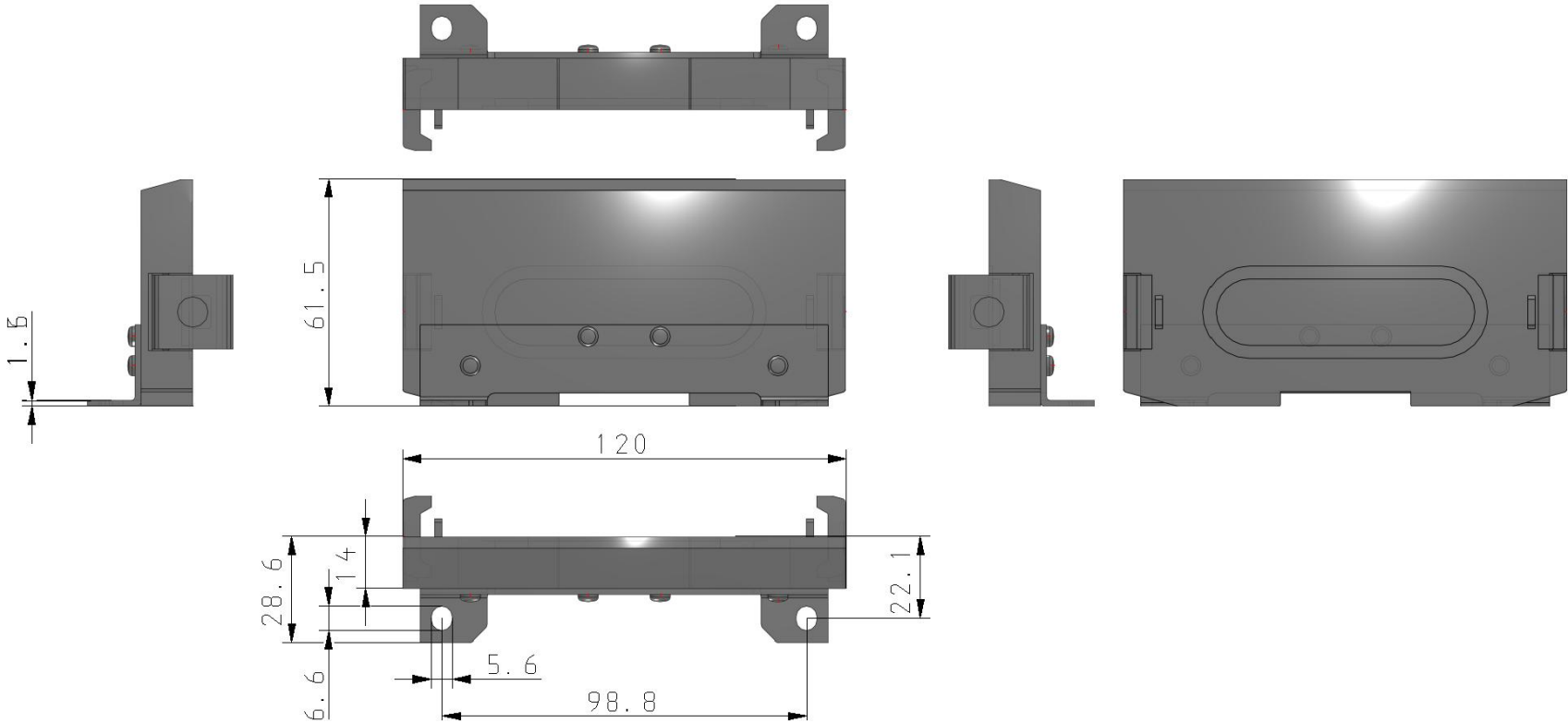

Additional information

Catalogue	EX245-A_EU.pdf
Declaration of conformity	newDoc_EX245_TF1V132EN-A.pdf.pdf newDoC_EX245_TF1Y094EN.pdf
Installation manuals	IM_EX245-SPN_TF2Z191EN.pdf IM_EX245-SPN_TF2Z184EN.pdf
Operation manuals	OM_EX245_OMW0011EN-B.pdf OM_EX245_OMU0020EN.pdf