


KEMET Part Number: MMK5102J400J01L15.0CBULK
 (F601JF102J400ALF0A, MMK5102J400J01L15,0CBULK)

MMK/F601, Film, Metallized Polyester, General Purpose, 1000 pF, 5%, 400 VDC, 85°C, Lead Spacing = 5mm

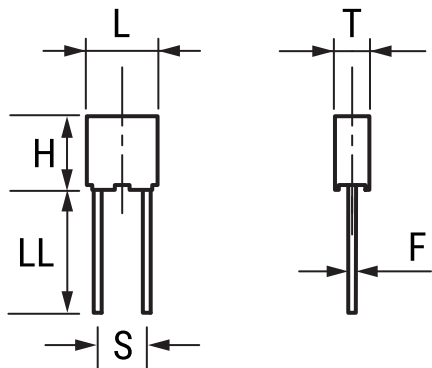

General Information	
Supplier:	KEMET
Series:	MMK/F601
Dielectric:	Metallized Polyester
Style:	Radial
Features:	DC Multipurpose Applications
RoHS:	Yes
Lead:	Wire Leads
Notes:	Not For New Design, Please Check Possible Alternative Parts (AltPart)

Dimensions	
L	7.2mm MAX
H	6.5mm MAX
T	2.5mm MAX
S	5mm +/-0.4mm
LL	15mm NOM
F	0.5mm NOM

Specifications	
Capacitance:	1000 pF
Capacitance Tolerance:	5%
Voltage AC:	200 VAC
Voltage DC:	400 VDC, 310 VDC (100C)
Temperature Range:	-55/+100C
Rated Temperature:	85°C
Insulation Resistance:	30 GOhms
Max dV/dt:	50 V/us

Packaging Specifications	
Packaging:	Bulk, Bag