
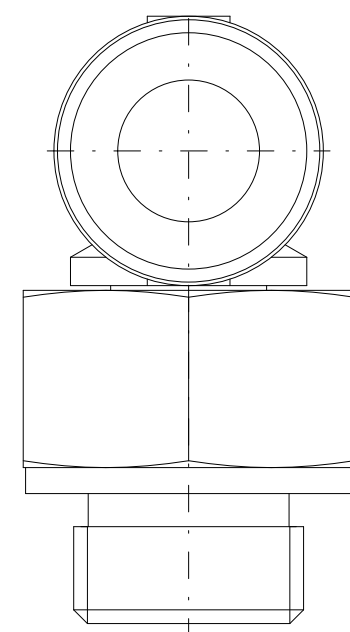
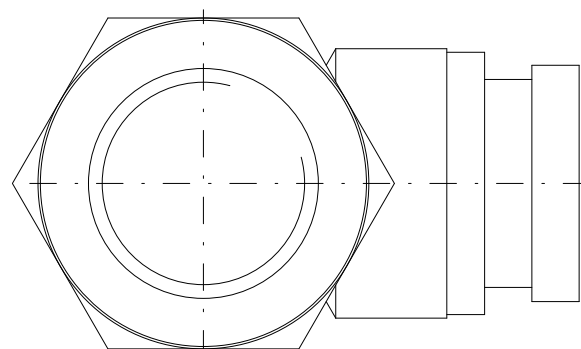
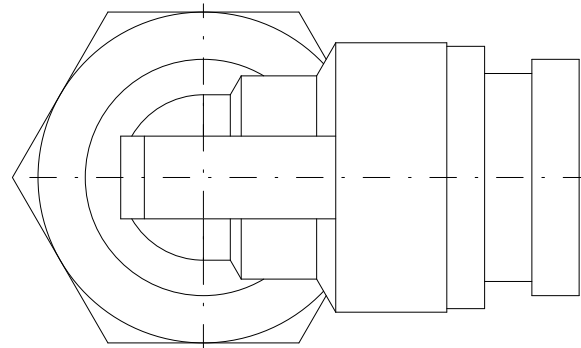
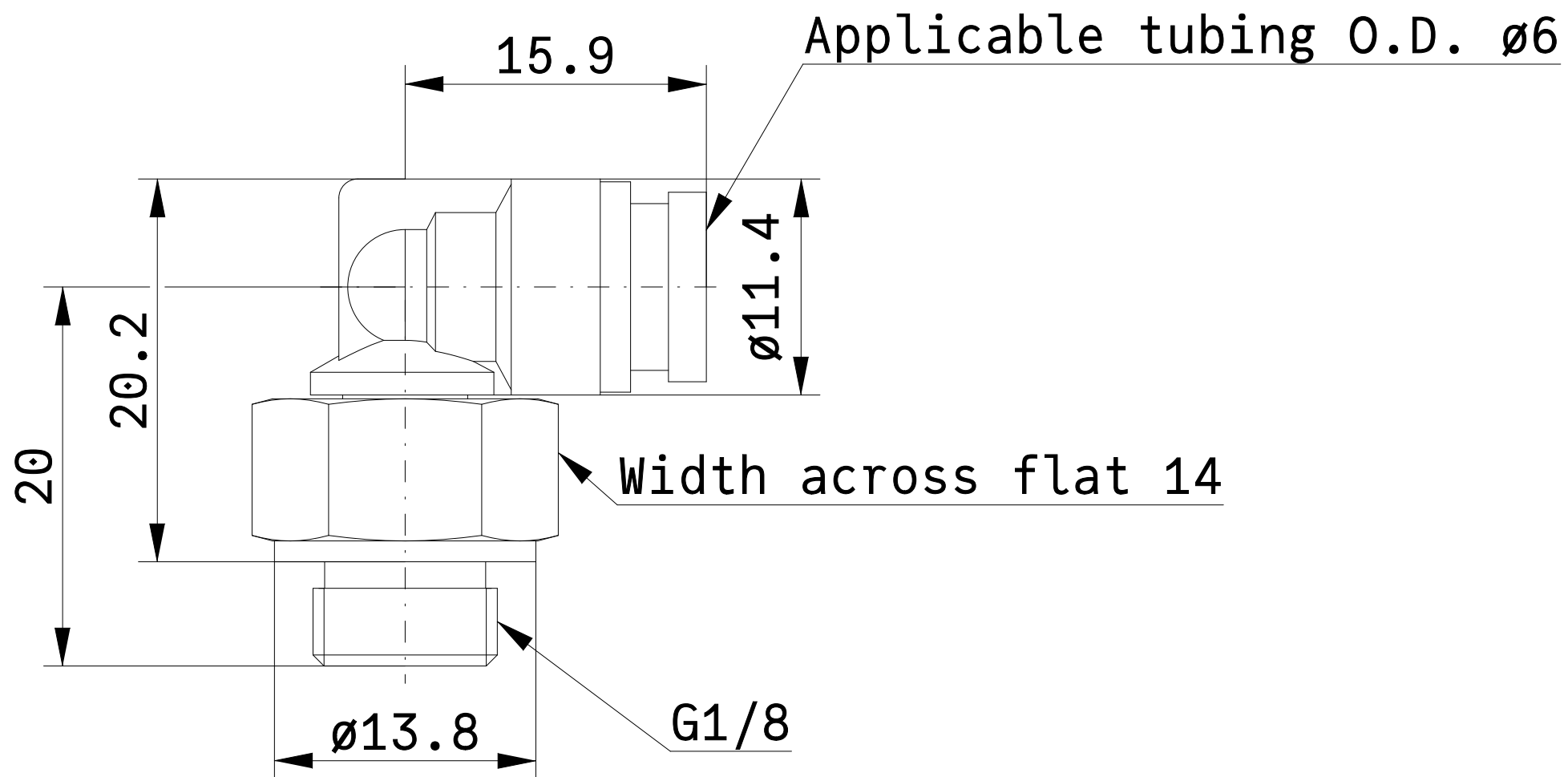
 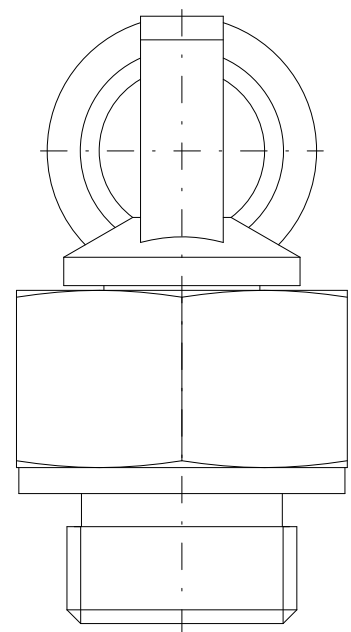





|             |                                                                                       |       |      |      |            |
|-------------|---------------------------------------------------------------------------------------|-------|------|------|------------|
| Projection  |  | Scale | Free | DATE | 03-31-2025 |
| Drawing No. | KQG2L06-G01-F                                                                         |       |      |      |            |

## KQG2L06-G01-F

Male Elbow

### Vue 3D

[Click here in Adobe Acrobat to activate the interactive 3D View.](#)

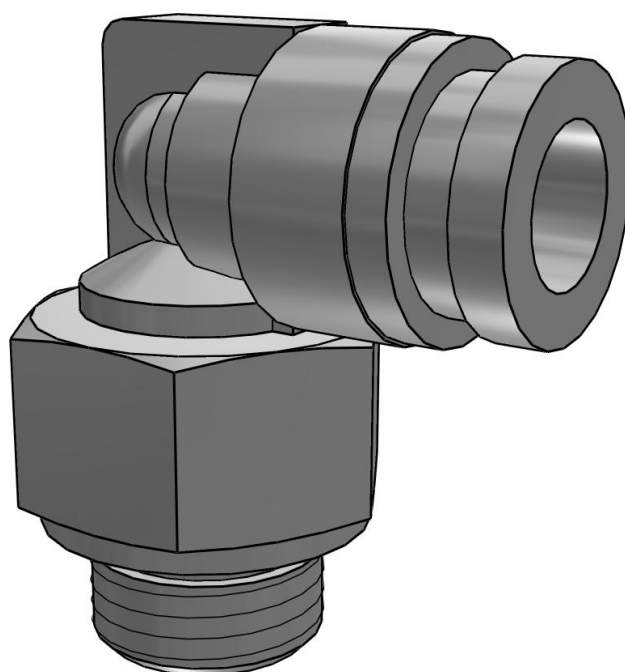

## KQG2L06-G01-F

Male Elbow

### Données techniques

|                                        |               |
|----------------------------------------|---------------|
| OD (Applicable tube O.D. / mm)         | ø6            |
| G (Connection thread)                  | 1/8           |
| MODEL (Model)                          | KQG2L06-G01-F |
| H (Width across flat / mm)             | 14            |
| D1 ( / mm)                             | 11.4          |
| D2 ( / mm)                             | 13.8          |
| L1 ( / mm)                             | 15.9          |
| L2 ( / mm)                             | 20.0          |
| A ( / mm)                              | 20.2          |
| M ( / mm)                              | 13.6          |
| EA (Effective area / mm <sup>2</sup> ) | 11.4          |
| CNSMASSEXACT (Mass / g)                | 16.6          |