

Superia Spot

SUPERIA SPOT LED IP44 BA 36° 830

0053387



Range features

- Integrated LED accent downlight (lifetime 30,000 hrs)
- IP44 ideal for bathrooms
- Easy installation
- Includes separate LED driver
- Diameter of cutout 68mm
- Diameter 100mm
- Available in white or brushed aluminium

LED

PRODUCT OVERVIEW

Ordering number	0053387
Light colour	Warm white
Technology	LED
Average life (Rated) (h)	30000
EAN code	5410288533872
Certifications	EC
Mount	Ceiling recessed
Housing	Steel
CRI (Ra)	80
LOR (%)	100
Beam angle(°)	36
Efficacy (Rated) (lm/w)	47
Voltage (V)	220-240
Colour	Brushed Aluminium
IP rating	44
IK rating	02

Superia Spot

SUPERIA SPOT LED IP44 BA 36° 830

0053387

DATA TABLE

General data

Technology	LED
Ordering number	0053387
Average life (Rated) (h)	30000
EAN code	5410288533872
Certifications	EC
Mount	Ceiling recessed
Long description	Integrated LED accent downlight (lifetime 30,000 hrs). IP44 ideal for bathrooms. Easy installation. Includes separate LED driver. Diameter of cutout 68mm . Diameter 100mm. Available in white or brushed aluminium
Product name	SUPERIA SPOT LED IP44 BA 36° 830
Control gear type	External
Environment	Interior
General application	Residential accent downlighting
Housing	Steel

Optical data

Light colour	Warm white
CRI (Ra)	80
LOR (%)	100
Beam angle(°)	36
Luminous flux (Nominal) (lm)	462
Distribution type	Direct

Electrical data

Efficacy (Rated) (lm/w)	47
Voltage (V)	220-240
Drive current (mA)	800mA
Electrical protection	CLASS II

Physical data

Weight (kg)	0.5
Colour	Brushed Aluminium
Lamp included	Yes
Height (mm)	50
Width (mm)	78
Length (mm)	78
IP rating	44
IK rating	02
Cutout diameter (mm)	68 ø
Cutout shape	Round
Recessed depth (mm)	50
Reflector material	Bright Aluminium Reflector

Superia Spot

SUPERIA SPOT LED IP44 BA 36° 830


0053387

Superia Spot

SUPERIA SPOT LED IP44 BA 36° 830

0053387

TECHNICAL DRAWINGS

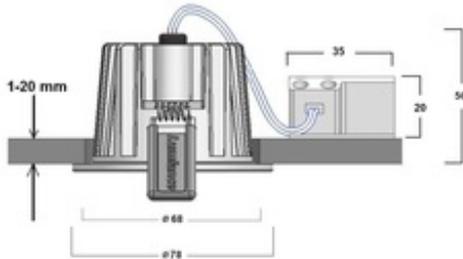

ENERGY LABEL

