



Model		
product brand name		SETRON
Type of the driving mechanism		others
General technical data		
Manner of function / of the operating hours counter		analog
Reset function		no
Protection class		
Protection class IP		IP20
Number		
Number of characters that can be displayed		7
Mechanical Design		
Height	mm	90
Height / of the front plate	mm	45
Width	mm	36
Installation depth	mm	64
Number of width units		2
Mounting type		DIN rail

Net weight

g

94

General Product Approval

Declaration of Conformity



UL

EG-Konf.

## Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/7KT5801>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/7KT5801/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=7KT5801](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=7KT5801)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

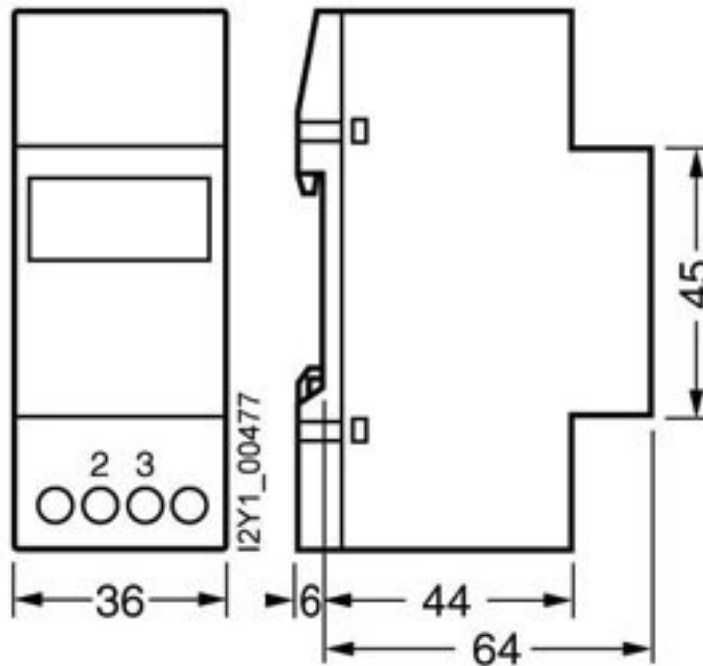

last modified:

08/31/2016