


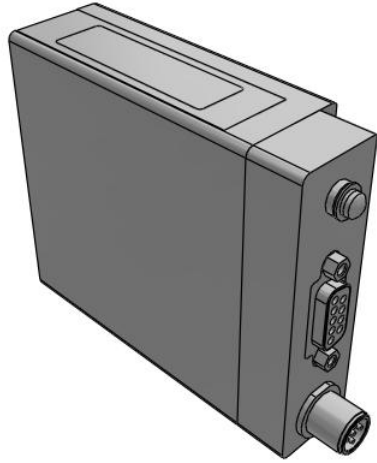




## EX260, Integrated Type (For Output) Serial Transmission System EX260-SPR5

### Datasheet

- Centralised & compact serial transmission system for output
- Compatible protocols: Ethernet POWERLINK, PROFINET, EtherNet/IP<sup>TM</sup>, EtherCAT®, PROFIBUS DP, DeviceNet<sup>TM</sup>, CC-Link, IO-Link, CANopen, Modbus, AS-Interface
- Up to 32 solenoids, up to 24 stations
- Applicable valve series: new SY, VQC, S0700, SV
- Up to IP67 enclosure compliant.

|                                         |                                                                      |
|-----------------------------------------|----------------------------------------------------------------------|
| Protocol                                | PR (PROFIBUS DP)                                                     |
| Output Polarity/Communication Connector | 5 [32 Outputs, -COM (PNP), D-sub Connector]                          |
| Maximum ambient temperature             | 50 °C                                                                |
| Minimum ambient temperature             | -10 °C                                                               |
| General power supply                    | 24 VDC                                                               |
| Conform to the European RoHS Directive  | Conform                                                              |
| Approvals                               | CE marking, UL (CSA) compatible                                      |
| Operating humidity range                | 35 to 85% RH (No condensation)                                       |
| Type of electrical connector            | D-sub                                                                |
| Version                                 | DP-V0                                                                |
| Number of outputs                       | 32                                                                   |
| SI unit output polarity                 | Source/PNP (Negative common)                                         |
| Communication speed                     | 9.6 k/19.2 k/45.45 k/93.75 k/<br>187.5 k/500 k/1.5 M/3 M/6 M/12 Mbps |
| Enclosure                               | IP40                                                                 |
| Weight                                  | 0.200 Kg                                                             |

## Dimensions

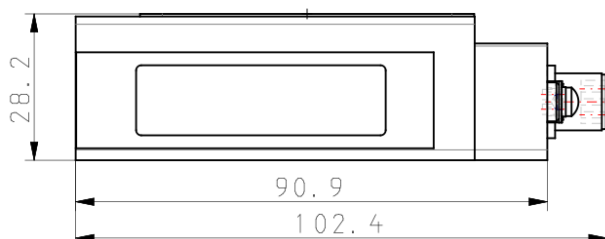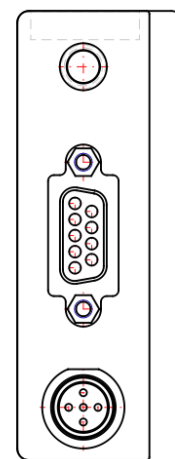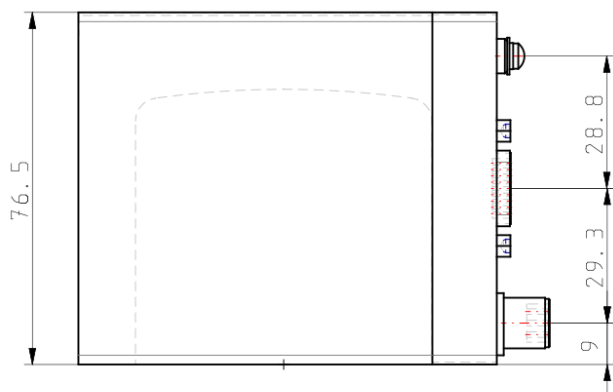

## Additional information

Catalogue

[EX260-C\\_EU.pdf](#)