

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Contact insert, M23, number of positions: 17, contact connection type: Pin, Crimp connection, series: NC, RC, RM, TU, UC, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

Commercial data

Item number	1241379
Packing unit	1 pc
Minimum order quantity	10 pc
Sales key	*****
Product key	ABRAFU
GTIN	4063151396626
Weight per piece (including packing)	10.7 g
Weight per piece (excluding packing)	5.45 g
Customs tariff number	85389099
Country of origin	DE

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Technical data

Notes

Assembly note	Integrated contacts: 12 x 1240882 and 5 x 1241571
---------------	---

Product properties

Product type	Contact insert
Series	NC
	RC
	RM
	TU
	UC
Application	Signal
Number of positions	17
Connection profile	17
Coding	N
Thread type	M23

Electrical properties

Contact	
Contact diameter	1 mm
Min. cross section	0.14 mm ²
Max. cross section	0.56 mm ²
Max. current	8 A
Nominal voltage U _N	48 V AC 74 V DC
Overvoltage category	III
Degree of pollution	3
Rated surge voltage	1.5 kV

Connection data

Connection method	Crimp connection
-------------------	------------------

Material specifications

Insulator material	PA66
Contact material	CuZn
Contact surface	Nickel-plated, gold coating

Connector

Direction of rotation	Standard
-----------------------	----------

Mechanical properties

Mechanical data	
Insertion/withdrawal cycles	50

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Environmental and real-life conditions

Ambient conditions

Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

RC-17P1N8D0000X - Contact insert


1241379

<https://www.phoenixcontact.com/in/products/1241379>



Drawings

Schematic diagram

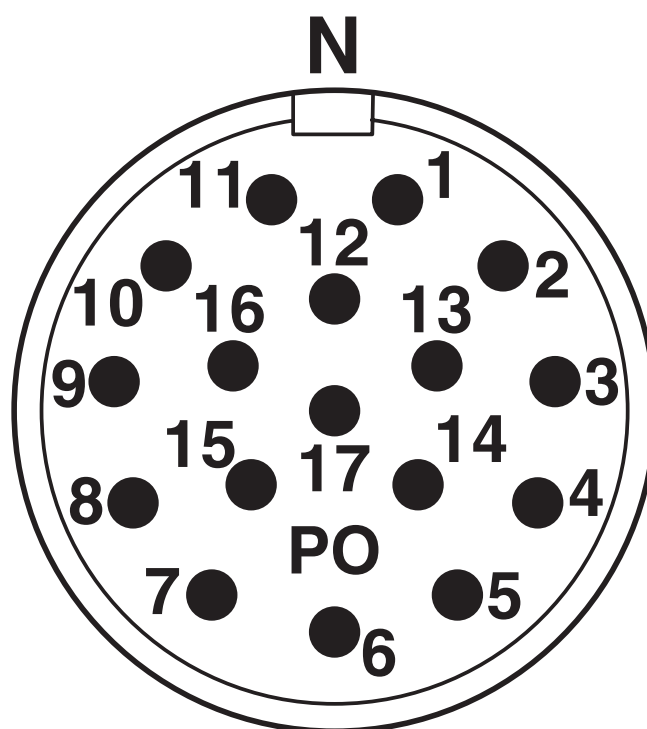

Connector pin assignment


RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Schematic diagram

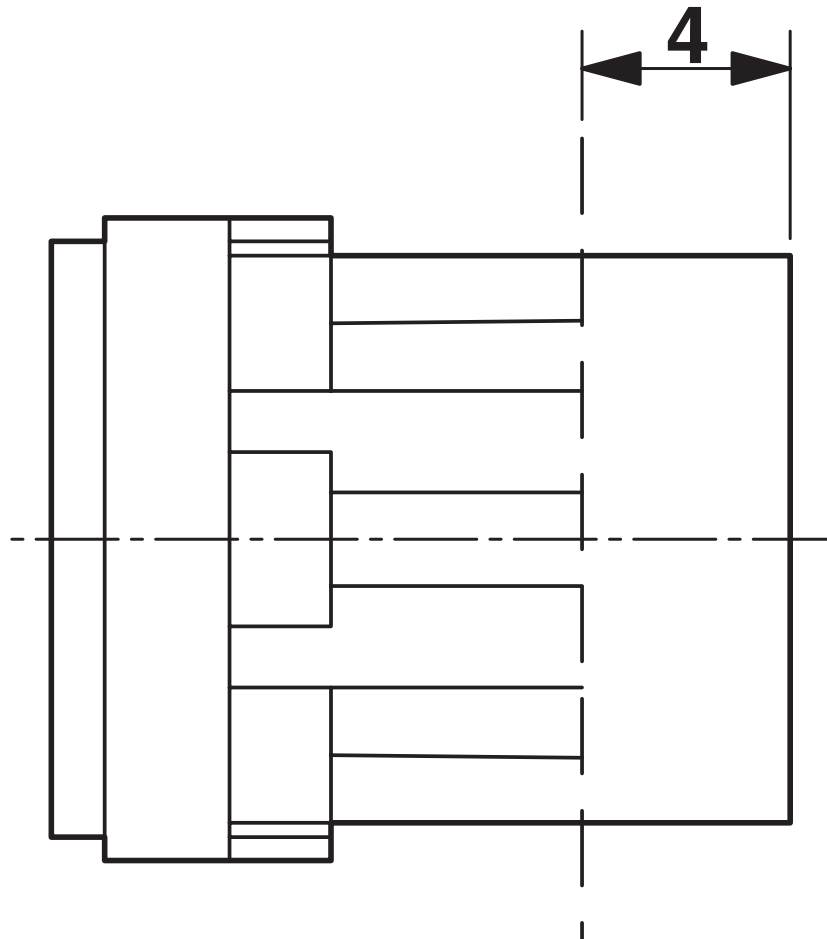

Dimensional drawing

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1241379>



EAC

Approval ID: 19060508

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Classifications

ECLASS

ECLASS-11.0	27440223
ECLASS-12.0	27440223
ECLASS-13.0	27440223

ETIM

ETIM 9.0	EC003557
----------	----------

RC-17P1N8D0000X - Contact insert



1241379

<https://www.phoenixcontact.com/in/products/1241379>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in