



Sample image

**Order symbol :** EKPK

**Product nr :** 3530315


**Description :** Base, PC

**Remarks :** Openings; 3x size 2 flange + 1x size 3 flange

**EAN :** 6418074000101

**El. number :**

- Finland : 3420123
- Denmark : 8212006580
- Sweden : 2537818

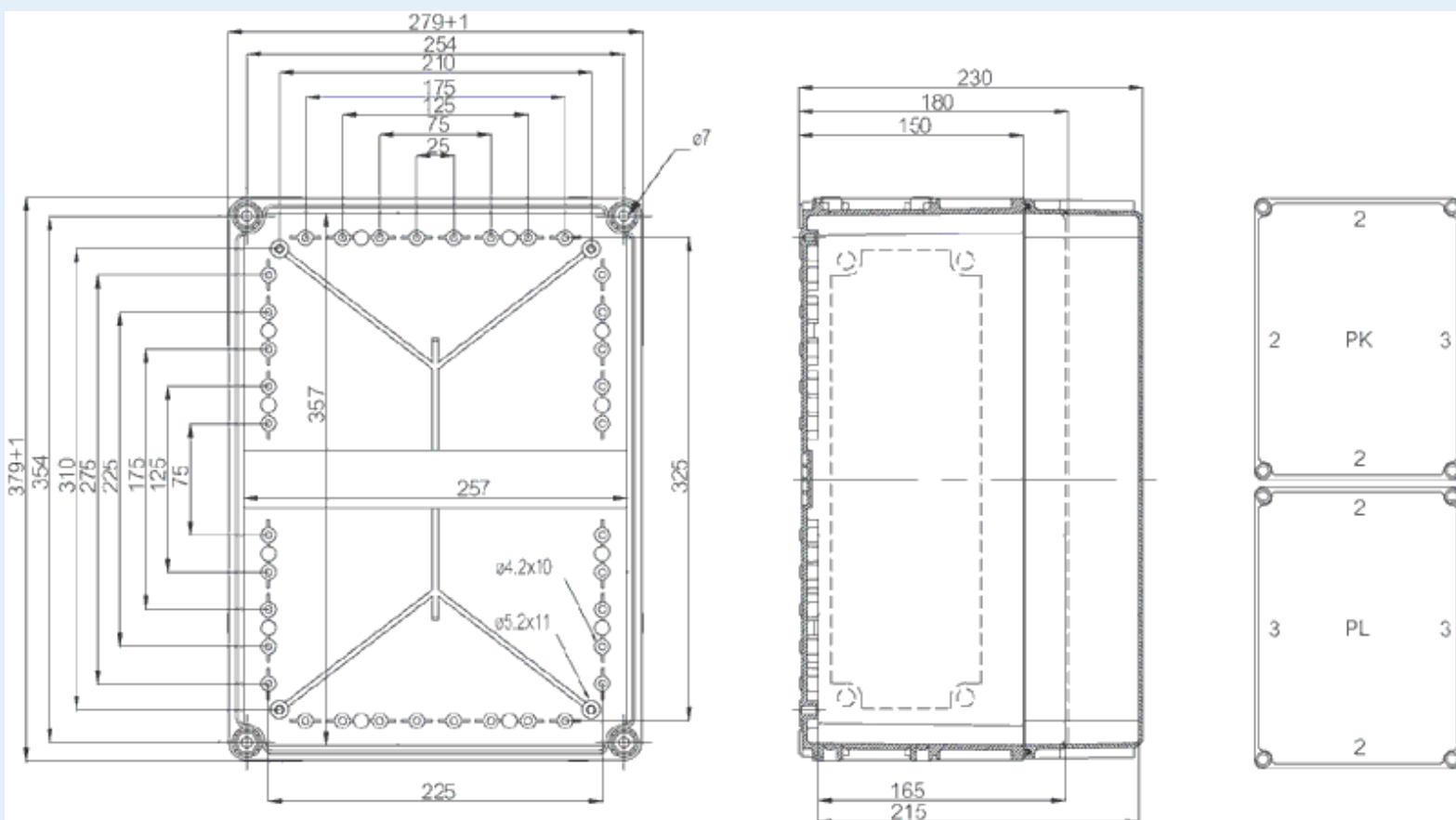

**Dimensions :**

| mm :   | Height | Width | Depth |
|--------|--------|-------|-------|
| 380    | 280    | 150   |       |
| inch : | 14.96  | 11.02 | 5.91  |

**Accessories :**

|        |                                                         |
|--------|---------------------------------------------------------|
| EKV 32 | DIN-35 Mounting rail, for enclosures:<br>(335 x 35 x 7) |
| EKV 22 | DIN-35 Mounting rail, for enclosures:                   |

|                    |               |
|--------------------|---------------|
| <b>Materials :</b> |               |
| Material :         | Polycarbonate |
| Base colour :      | RAL_7035      |

|                               |             |
|-------------------------------|-------------|
| <b>Temperatures :</b>         |             |
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

|                    |                                                           |
|--------------------|-----------------------------------------------------------|
|                    | (235 x 35 x 7)                                            |
| EKPZR              | Extension frame, for enclosures:<br>(380 x 280 x 50)      |
| EKPVT              | Mounting plate, for enclosures:<br>(338 x 238 x 1.5)      |
| MPI EKP 3828       | Multiperforated plastic mounting plate<br>(338 x 238 x 4) |
| DRS EKP 2838 2x19M | DIN rail set<br>(364 x 264 x 90)                          |
| DRS EKP 3828 3x14M | DIN rail set<br>(364 x 264 x 90)                          |

|                                   |                   |
|-----------------------------------|-------------------|
| <b>Ratings :</b>                  |                   |
| electrical_insulation :           | Totally insulated |
| UV resistance :                   | UL 746C           |
| Flammability Rating :             | UL 94 V0          |
| Glow Wire Test (IEC 695-2-1) °C : | 960C              |

|                       |  |
|-----------------------|--|
| <b>Certificates :</b> |  |
| SGSFIMKO_EK           |  |