

TIME COUNTER 48X48MM AC 115V 50HZ WITHOUT
BLIND 55X55MM



Model		
product brand name		SENTRON
Type of the driving mechanism		others
General technical data		
Diameter / of the front panel cutout	mm	50.2
Electrical input frequency / minimum	Hz	50
Electrical input frequency / maximum	Hz	50
Manner of function / of the operating hours counter		analog
Reset function		no
Protection class		
Protection class IP		IP20
Number		
Number of characters that can be displayed		7
Mechanical Design		
Height	mm	45
Height / of the front plate	mm	48
Width	mm	45

Installation depth	mm	34
Mounting type		front panel mounting
Net weight	g	55

General Product Approval	Declaration of Conformity
--------------------------	---------------------------



Further information

Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>


Industry Mall (Online ordering system)
<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/7KT5501>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<http://support.automation.siemens.com/WW/view/en/7KT5501/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=7KT5501

CAX-Online-Generator
<http://www.siemens.com/cax>

Tender specifications
<http://ausschreibungstexte.siemens.com/tiplv>

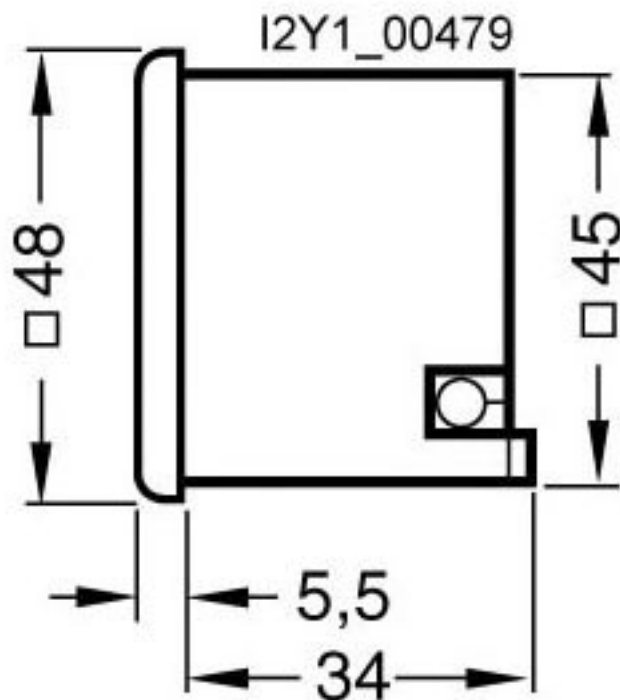

last modified:

08/30/2016