



925366-8 -- 1 of 1 products

AMPMODU

Locking Clip, Mod. IV and Short Point Products


General **INFO**

Sales **INFO**

Customer Drawings **SPECIFICATIONS**

Ohne Verriegelung

Without Strain

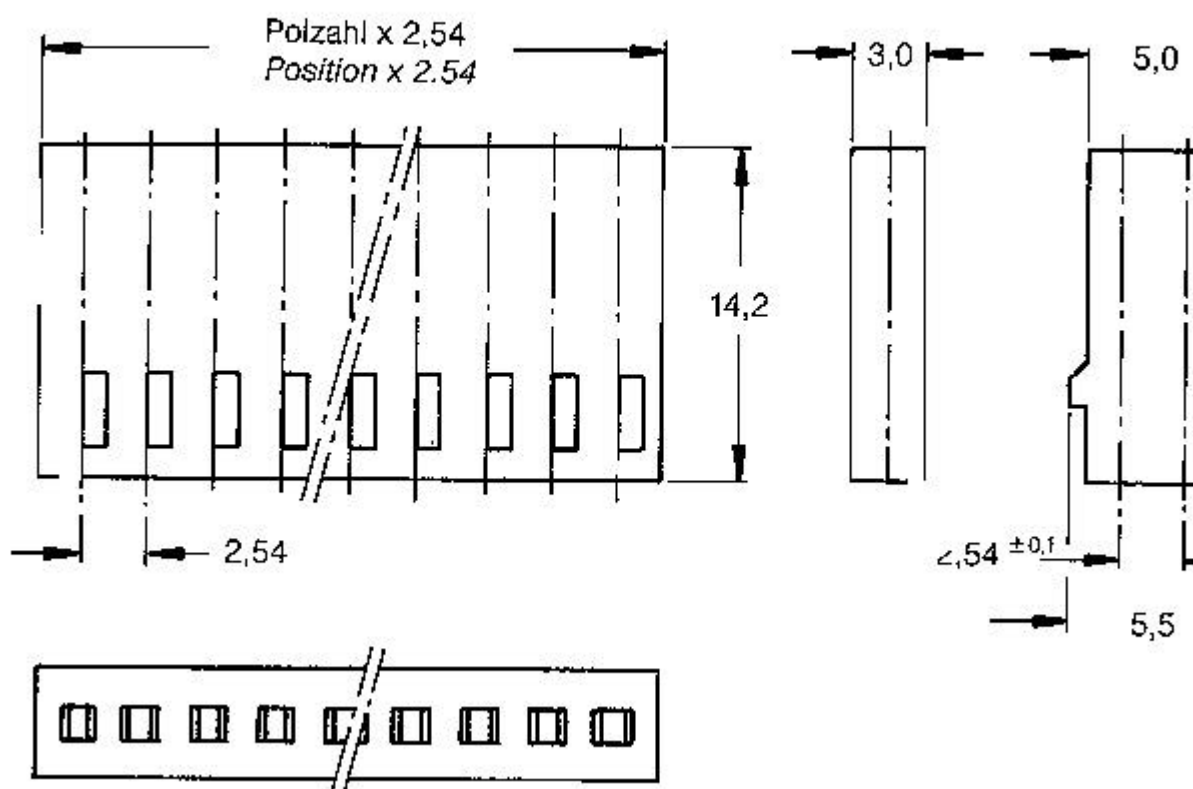

Line art represents typical product only.

<i>Searchable Features:</i>	
# of Positions	8
# of Rows	Single
Centerline Spacing	.100 [2.54] in. [mm]
Housing Configuration	Both Ends Closed
Contact Type	Mod IV, Mod V
Mating Polarization	No
Mating Connector Lock	Without
Strain Relief	Without
Keyed	No
<i>Other Properties:</i>	
Housing Material	Nylon
Housing Flammability Rating	UL 94-HB
Housing Color	Green

[[Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#)]
[Top of Page](#)