




LED/Multiled	LED	Optimum voltage (V)	12Vdc	Intensity	1000mcd@20mA
Mounting Size	14mm	Rectifier			
Mounting Finish	Black Chrome Bezel	AC current			
Protection	IP67	DC current	20mA (max))		
Mount Holder	Prominent	Voltage Tolerance (%)	10%		
Chip Qty	1	Optimum temperature (°C)	-40°C...+85°C		
Indicator colour	White	Storage temperature (°C)			
Wavelength (nm)	X0.31/Y0.31	Contact Tab x 2	22AWG wire		

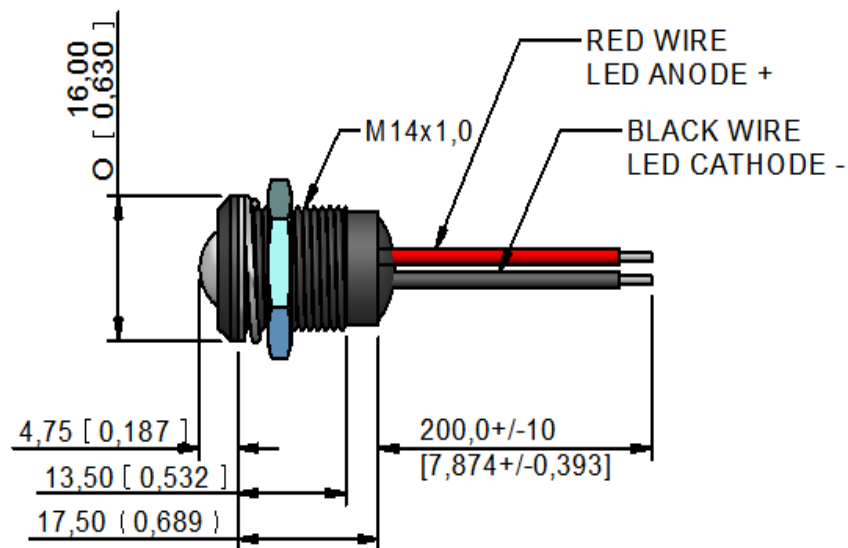

Dimension in mm (typical), not to scale.

We reserve the right to make changes without further notice to this product to improve reliability, function or design.