



# Xitanium Outdoor SELV (Constant Current)

LED Driver Outdoor 40W/1.75A-24V 230V

Constant current LED driver for outdoor applications

## Product data

### • Product Data

Order code	913700625082
Full product code	871150091273230
Full product name	LED Driver Outdoor 40W/ 1.75A-24V 230V
Order product name	LED Driver Outdoor 40W/ 1.75A-24V 230V
Pieces per pack	1
Packs per outerbox	12
Bar code on pack - EAN1	8711500912732
Bar code on outerbox - EAN3	8711500912749
Logistic code(s) - 12NC	913700625082
Net weight per piece	0.399 kg

### • General Characteristics

Average Lifetime	50000 hr
Input Frequency	50 Hz
Type Version	mk2
IP Classification	IP66
Survival rate	90 %

### • Operating Characteristics

Output Power Range	40.8 W
Input Power max	48 W
Output Voltage Range	5.6-24 V

Output Current Range (mA)	1750
Input Current max	240 mA
Output Current Tolerance	-5 (min), 5 (max) %
Type of Dimming	1-10V
Input Voltage Range (AC)	207-264 V

### • Temperature Characteristics

T-case maximum	85 C
----------------	------

### • Approval&Application Char's

ENEC certificate	Yes
CE marking	Yes

### • Product Dimensions


Length A1	88.9 mm
Width B1	83 mm
Height C1	38 mm
Fixing Hole Diameter D1	3.8 mm
Fixing Hole Distance Width B2	70 mm
Fixing Hole Distance Length A2	76 mm

# PHILIPS

sense and simplicity

# Titanium Outdoor SELV (Constant Current)

## Dimensional drawing

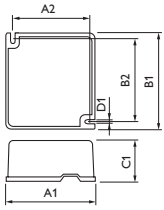

Product	A1 (Norm)	A2 (Norm)	B1 (Norm)	B2 (Norm)	C1 (Norm)	D1 (Norm)
LED Driver Outdoor 40W/1.75A-24V 230V	88.9	76	83	70	38	3.8



© 2011 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2011, January 29  
data subject to change