


R.ET – ¼" 6 Point Metric Sockets

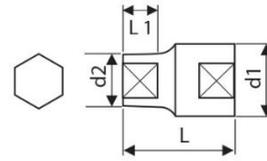

Description:

- **6-Point OGV® Profile** – Maximising the contact surface with the nut and minimising damage to the fastener
- **NECK-DOWN DESIGN** - Facilitating the use in narrow spaces
- **Matte finish**
- **DIN 3124, ISO 1711-1, ISO 2725-1, NF ISO 1711-1, NF ISO 2725-1**

	Fastener Size (mm)	Square Drive	Length L1 (mm)	Diameter D2 (mm)	Weight (g)
R.4HT	4	¼"	22	11	6
R.4.5HT	4.5	¼"	22	11	6
R.5HT	5	¼"	22	11	7
R.5.5HT	5.5	¼"	22	11	8
R.6HT	6	¼"	22	11	10
R.7HT	7	¼"	22	12	12
R.8HT	8	¼"	22	12	16
R.9HT	9	¼"	22	13.2	16
R.10HT	10	¼"	22	14.7	22
R.11HT	11	¼"	22	15.8	24
R.12HT	12	¼"	22	17	30
R.13HT	13	¼"	22	17.7	30
R.14HT	14	¼"	22	18.7	40