


# RS Pro M12 Panel Mount Male, 4W, 300mm, M16x1.5

RS Stock No: 144-7625

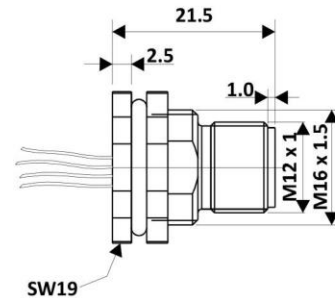


All dimensions are in mm.

## General Specification

Rated Operational Voltage	250 V
Current Rating	4A
Insulation Resistance	>= 100 MΩ
Temperature Range	-25°C ... +75°C
Degree of Protection	IP67

## Pin Assignment

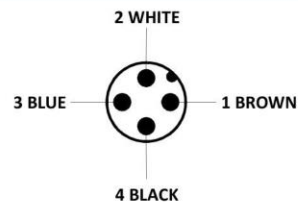

## Material Specification

Housing Material	Brass Ni Plated
Contact	Cu-Zn
Contact Plating	Gold Plated
Contact Carrier	Nylon 66
O-Ring	Neoprene
Pole	4
Clamp Nut	M16 x 1.5

## Cable Specification

Cross Section of Wire	0.34 sq.mm
Termination	Partially Stripped
Cable length	300 mm