


## Technical data sheet

Article number:  
111-12300

WSS

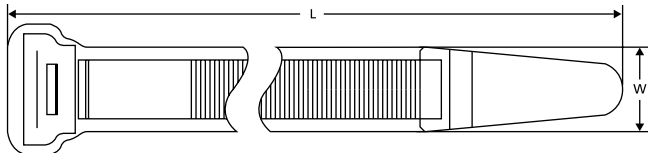

<b>Product Group</b>	Cable ties for hose and convoluted tubing
<b>Product Family</b>	WS-Series for heavy duty applications
<b>Material</b>	Polyamide 6.6, high impact modified, heat and UV-stabilised (PA66HIRHSUV)
<b>Colour</b>	Black (BK)
<b>Application Range</b>	High Temperature and Outdoor Use
<b>Application Tool</b>	ProCut 9 no battery, MK9P, MK9P w/ Upper air, EVO9SP, EVO9HT, EVO9i, EVO9iSP, EVO9iHT
<b>Bundle Ø max.</b>	57.1 mm
<b>Bundle Ø min.</b>	9.5 mm
<b>Flammability</b>	UL 94 HB
<b>Halogen-free</b>	Yes
<b>Length (L)</b>	230.0 mm
<b>Min.Tensile Strength</b>	535 N
<b>Operating Temperature</b>	-40 °C to +105 °C
<b>Package Content packed in</b>	pack
<b>Pack Cont.</b>	300 pcs.
<b>Releasable Closure (Yes/No)</b>	No
<b>Thickness (T)</b>	1.4 mm
<b>Toothing (Serration)</b>	Inside Serrated
<b>Variant</b>	Inside Serrated
<b>Weight/Unit</b>	0.00435 kg
<b>Width (W)</b>	12.7 mm

