

# Housing - HC-HPR-B24-SHFH-2SSM40-EMR-BK - 1411063

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 box mounting base, for screw locking, HPR series, with 2 x M40 gland, for increased environmental and EMC requirements



## Key commercial data

Packing unit	1 pc
GTIN	 4 046356 921695
Weight per Piece (excluding packing)	22.22 g
Custom tariff number	85389099
Country of origin	China

## Technical data

### Dimensions

Height	111 mm
Width	80 mm
Length	216 mm

### Ambient conditions

Degree of protection of housing (IP)	IP68 (0.5 bar, 24 h)
	IP69K
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Note	For contact inserts HC-B24, BB46, D64, DD108, M
Type	B24
Housing type	Box mounting bases
Locking type	For screw locking
No. of cable outlets	2
Cable exit	Lateral
Screw connection	none
Type of the screw connection	2x M40

# Housing - HC-HPR-B24-SHFH-2SSM40-EMR-BK - 1411063

## Technical data

### General

Protective cover	No
Housing material	Aluminum die-cast
Housing surface material	Powder-coated, black
Seal material	NBR

## Classifications

### eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261203
eCl@ss 8.0	27440202

### ETIM

ETIM 4.0	EC000437
ETIM 5.0	EC000437

## Approvals

### Approvals

---

Approvals

EAC / GL

---

Ex Approvals

---

Approvals submitted

---

### Approval details

EAC
-----

GL
----

## Accessories

Accessories

Full screw connection

## Housing - HC-HPR-B24-SHFH-2SSM40-EMR-BK - 1411063

### Accessories

Cable gland - G-INS-M40-M68N-PNES-GY - 1411128



Cable gland, Cable gland material: Polyamide 6, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: silver grey

---

Cable gland - G-INS-M40-M68N-PNES-BK - 1411137



Cable gland, Cable gland material: Polyamide 6, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: jet black

---

Cable gland - G-INS-M40-M68N-NNES-S - 1411167



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: silver

---

Cable gland - HC-M-KV-M40(27-34) - 1607729



Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 27 ... 34 mm, WAF 50, screw connection: M40

---

Cable gland - G-INSEC-M40-M68N-NCRS-S - 1411192



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 19 mm ... 27 mm, Shielding: Yes, Connecting thread: M40, Color: silver

---

# Housing - HC-HPR-B24-SHFH-2SSM40-EMR-BK - 1411063

## Accessories

Cable gland - HC-M-KV-Z-M40 - 1646175



Metal screw connection with strain relief clamp, thread length: 8 mm, cable sealing area: 24 - 33 mm, clamping area: 26 - 36 mm, SW 50, screw connection: M40

Plug for cable screw gland

Filler plugs - HC-M-BS-M40 - 1645875



Filler plug, metal, size: M40

Reducing adapter


Reducing adapter - REDUC-M-KV-M40/M32 - 1647640



Reducing adapter, M40 on M32, incl. O-ring

## Drawings

Dimensioned drawing

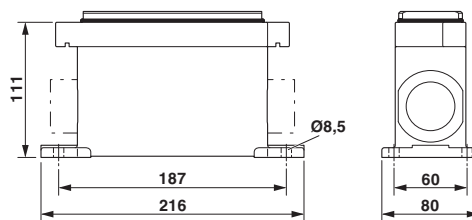

Dimensional drawing