


5520569

<https://www.phoenixcontact.com/in/products/5520569>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

VARIOFACE relay module, fixed, 2PDT

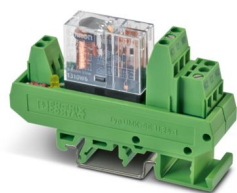

Commercial data

Item number	5520569
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	*****
Product key	DK61Y2
GTIN	4046356687737
Weight per piece (including packing)	53.3 g
Weight per piece (excluding packing)	33.33 g
Customs tariff number	85364190
Country of origin	US

UMK 22 REL 24 VAC/21-21 - Active module



5520569

<https://www.phoenixcontact.com/in/products/5520569>

Technical data

Notes

Trade restriction

CE note

The products are offered exclusively for export outside the EU and the European Economic Area.

Product properties

Product type

Relay Module

Input data

Nominal input voltage U_N

24 V AC

Input voltage range in reference to U_N

0.8 ... 1.1

Input voltage range

19.2 V AC ... 26.4 V AC

Dimensions

Width

22.5 mm

Height

77 mm

Depth

50 mm

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)

-20 °C ... 65 °C

Ambient temperature (storage/transport)

-40 °C ... 85 °C

Mounting

Mounting type

DIN rail mounting

UMK 22 REL 24 VAC/21-21 - Active module



5520569

<https://www.phoenixcontact.com/in/products/5520569>

Classifications

ECLASS

ECLASS-11.0	27371601
ECLASS-12.0	27371601
ECLASS-13.0	27371601

ETIM

ETIM 9.0	EC001437
----------	----------

UNSPSC

UNSPSC 21.0	39122300
-------------	----------

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------