

Features

- HDMI M-F
- Length: 16cm
- Colour: Black

RS PRO 0.16m High Speed with Ethernet HDMI Stub M-F

RS Stock No. 0839390



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

HDMI stub for use with faceplates, HDMI v1.4 which is now called HDMI High Speed with Ethernet as version numbers can no longer be used on cables. The stub comes with two mounting screws.

General Specifications


Connector 1	HDMI (Panel Mount)
Connector 1 Gender	Female
Connector 2	HDMI
Connector 2 Gender	Male
Length	16cm
Colour	Black
HDMI Version	High Speed with Ethernet

Approvals

Standards Met	CE UKCA ROHS REACH
---------------	--------------------

Similar Products

Stock No.	Brand	Product Name
0839389	RS PRO	0.15m High Speed with Ethernet HDMI Stub F-F
0839390	RS PRO	0.16m High Speed with Ethernet HDMI Stub M-F

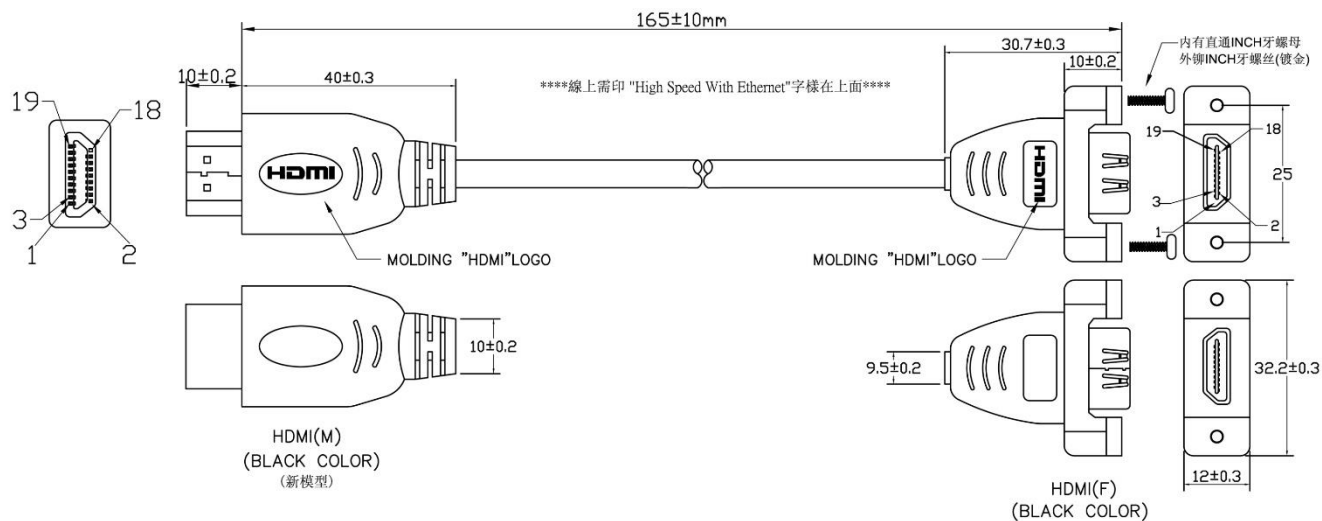


NOTE:

包装方式:空白OPP袋+料号贴纸.

(新模型)

- CABLE: 28AWG, UL20276, AL+B-FOIL, [(#28*1P+AL)*5PCS+#28*4C+D]+AM+B, BLACK COLOR, OD=7.3±0.2mm, PVC JACKET
- LENGTH: 165MM.
- CONNECTORS: HDMI19P(F)*1PCS HDMI19P(M)*1PCS (BLACK INSULATOR) (镀金头).
镀金INCH牙螺丝*2PCS, 镀金鑽石纹咬花螺母*2PCS
- MOLD: MOLDING TYPE.
- CONTACTS:

HDMI(M)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
HDMI(F)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
	PAIR		G	PAIR		G	PAIR		G	PAIR		G	PAIR		G	28AWG				SHELL
- Test machine test condition.
A. 100% OPEN, SHORT & INTERMITTANCE TEST.
B. CONDUCTOR RESISTANCE: 3ohms MAX:
C. INSULATION RESISTANCE: 5M Min./10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.

 

螺丝*2PCS



鑽石纹咬花螺母*2PCS