


Type K Insulated Flat Pair Thermocouple Cable (ANSI)

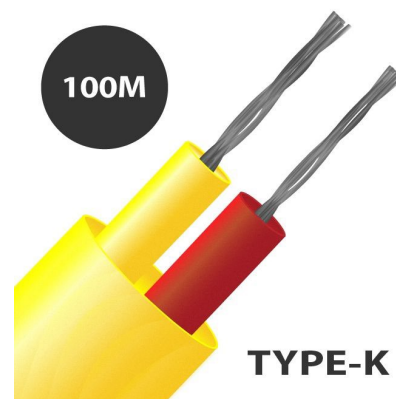

Features

- Ideal for use as general-purpose extension wire in high-temperature environments
- Good mechanical strength and flexibility
- Resistant to oils, acids and other adverse fluids, gasses, steam & pressure



Specification

Cable Length	100 m
Cable Type	Single Pair of PFA Insulated Conductors, Laid Flat with PFA Jacket
Conductors	7
Conductor Cross Section	0.219 mm ²
Outer Colour	Yellow
+ Colour	Yellow
- Colour	Red
Drain Wire	No
Insulation Material	PFA
Loop Resistance	4.5 Ohms
Max. Temperature	+260 °C
Min. Temperature	-75 °C
+ Conductor	Nickel Chromium
- Conductor	Nickel Aluminium
Screen	PET
Standards Met	Colour Code (Cores & Jacket) to IEC-584-3
Thermocouple Type	K
Tolerance	Class 1

Art. Nr.
RND 410-00060