


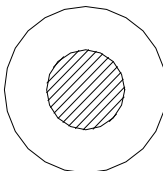

Datasheet

Product Name:	UL1180 26AWG
Product Discription:	UL1180 26AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		300Vac(UL allows 600V for electronic use only).			Conductor		Stranded Sliver plated copper					
Rated Temperature:		200℃,Optional - 80 ℃ Oil, Gasoline Resistant.			Size(AWG)		26					
Reference Standard:		UL758			Construction(±0.008mm)		7/0.16					
Cross Section					Stranded Dia.(mm)Ref.		0.48					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.33					
					Insulation Dia.(±0.08mm)		1.22					
Marking					Remark:							
No marking on the cable jacket, have UL label on the Reel.					8740172 Red		8740175 Blue		8740194 Grey		8740197 Violet	
					8740169 Black		8740179 White		8740181 Yellow			
					8740163 Brown		8740188 Green		8740185 Orange			
Applications					Characteristics				Customer Approve			
For internal wiring of electronic and electrical equipment					Test Item		Standard Value		<div>Seal & Stamp</div> <div>Signature:</div> <div>Date:</div>			
					Test Material		PTFE(ROHS)					
					Insulation resistance(20℃ MΩ*m		1000					
					Vol. Tesr(AC.V.60S) (V)		2000					
					Flammability Test		Horizontal flame					
Revisions					Max.DC Resistance(20℃ Ω/km)		127(MAX)					
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Danniel	Jason	24/04/2015								