
 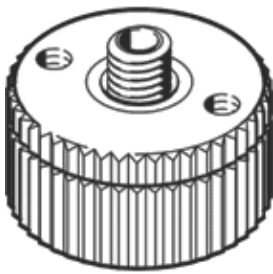


# vacuum filter

## ESF-4B

Part number: 191204

FESTO



### Data sheet

Feature	Value
Assembly position	Any
Grade of filtration	10 µm
Operating pressure	-0.95 ... 4 bar
Flow rate at vacuum pressure of -0.75 bar	270 l/min
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	0 ... 60 °C
Product weight	19 g
Mounting type	with external (male) thread Via vacuum port
Pneumatic connection	M6
Vacuum connection	M6
Materials note	Free of copper and PTFE Conforms to RoHS
Material seals	NBR
Material filter	PVF
Material housing	Aluminium Nickel-plated brass