

Breadboard




SPECIFICATIONS:

Pitch	2.54 mm
3 Terminal strips	1920 tie-point
5 Distribution strips	500 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Temp. range	-25°C ~ 80°C
Strip length	7-8 mm



Art. Nr.

RND 255-00001

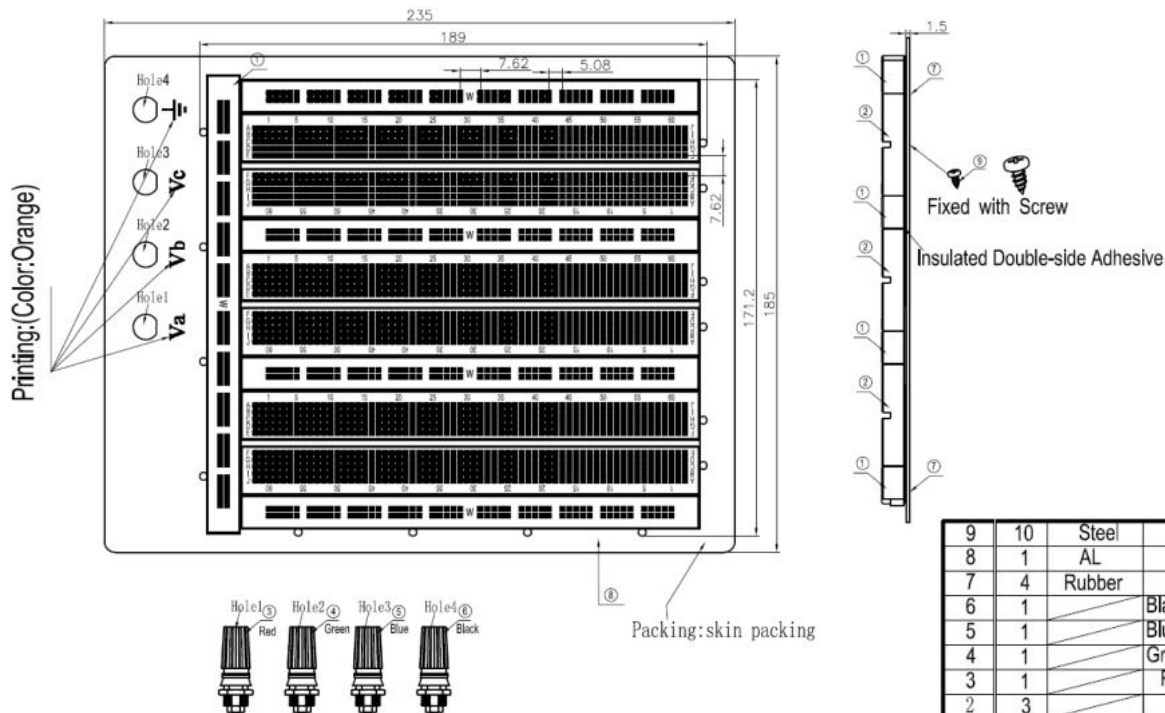

9	10	Steel	Black Zn
8	1	AL	Black paint
7	4	Rubber	UL94 V-2
6	1		Black Binding Post
5	1		Blue Binding Post
4	1		Green Binding Post
3	1		Red Binding Post
2	3		Terminal Strips
1	5		Distribution Strips
NO.	Q' TY	MATERIAL	NOTES

TOLERANCES EXCEPT AS NOTED

	linear dimension					fillet		chamfer		short angle sid			≡	—	□	//	⊥
variable range	to 6	over 6 to 30	over 30 to 120	over 120 to 480	all	to 6	over 6 to 10	to 10 to 50	over 50 to 120	over 120 to	all	to 5	over 5 to 30	over 30 to 120	over 120 to		
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1°	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

