




Technical Information	Colour	Colour Temp (White only)	Light Output Lumens/m	RS Part Number
<ul style="list-style-type: none"> • LED: SMD3528 60LED/M • Voltage: 12VDC • Current: 400mA • Max consumption: (W/m) power 4.8 • Dimensions: 10mm x 1000mm (1 Metre) • Beam angle: 120° • IP20 	Cool White	5500 -7000K	550	
	White	4000 -4500K	500	1533639
	Warm White	2700 -3200K	420	1533636
	Red	N/A	250	
	Green	N/A	350	1533648
	Blue	N/A	150	1533654
	Yellow	N/A	250	1533629

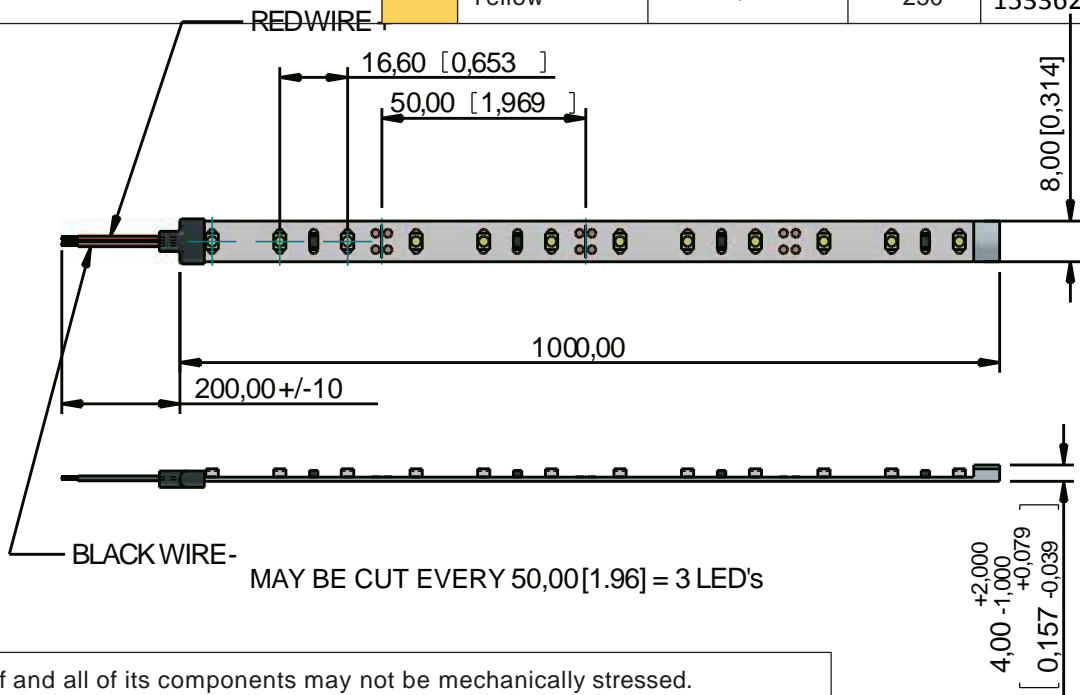

The strip itself and all of its components may not be mechanically stressed. Assembly must not damage or destroy conducting paths on the circuit board. Correct electrical polarity needs to be observed, wrong polarity may destroy the strip. When mounting on a metallic or otherwise conductive surfaces, there needs to be electrical isolation points between strip and the mounting surface. Caution needs to be taken after cutting the strip that exposed ends are insulated.