



SETRON, cylindrical fuse link, 22x58 mm, 20 A, aM, Un AC: 690 V

Figure similar

Model			
product brand name		SETRON	
product designation		Cylindrical fuse link	
General technical data			
operating class of the fuse link		aM	
type of voltage of the operating voltage		AC	
supply voltage at DC		250 V	
Dissipation			
power loss [W]		1.2 W	
power loss [W] for rated value of the current at AC in hot operating state per pole		1 W	
Main circuit			
operational current rated value		20 A	
Product details			
product component striker		No	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		52 g	
Approvals Certificates			
General Product Approval		other	Environment




[Miscellaneous](#)

[Confirmation](#)

[Environmental Confirmations](#)

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	
Industry Mall (Online ordering system)	
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW8207-1	
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	
https://support.industry.siemens.com/cs/ww/en/ps/3NW8207-1	
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)	
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW8207-1	
CAx-Online-Generator	
http://www.siemens.com/cax	
Tender specifications	
http://www.siemens.com/specifications	

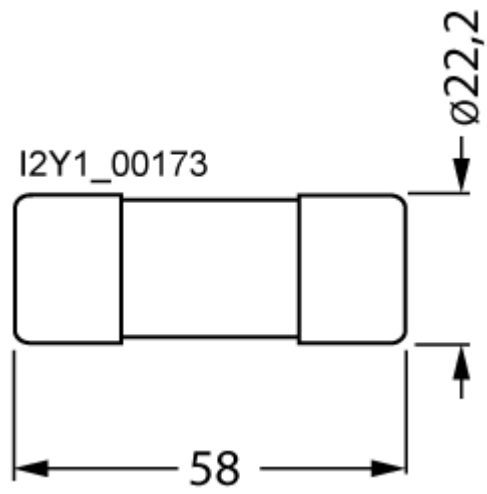

last modified:

4/11/2025 

