


Universe	Professional
Type	Lighting
Category	New ultra-compact and versatile headlamps
Subcategory	New ultra-compact and versatile headlamps




Hybrid
CONCEPT®

ARIA 1


Casting 350 lumens, the ARIA 1 compact headlamp was specifically designed to be used by tradespeople and maintenance professionals. Durable, it is fall and impact resistant. It is also waterproof and dustproof, making it suitable for various work conditions. Easy to use, with a single button for controlling all lamp functions. The uniform flood beam offers comfortable close-range vision. It is convenient and can be worn on the head, around the neck, and on different types of helmets, using mounting plates that are available as accessories. ARIA 1 comes with three standard batteries and is also compatible with the CORE rechargeable battery, with its HYBRID CONCEPT design.

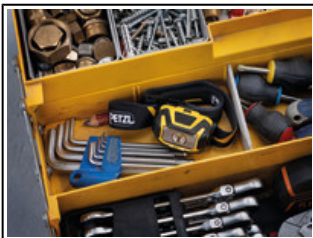

Compact, the ARIA 1 headlamp can be easily stored in a toolbox.

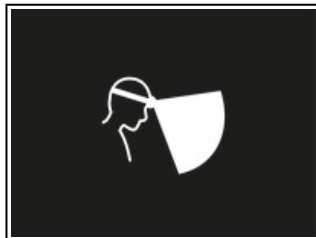

The wide, uniform beam provides comfortable lighting for close-range work.

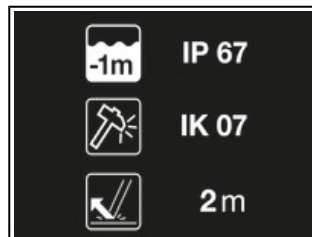

Dustproof and waterproof (IP67), impact resistant (IK07), and fall resistant up to 2 meters, the headlamp is ideal for professional work conditions.



HYBRID CONCEPT design: ARIA 1 comes with three standard batteries and is also compatible with the CORE rechargeable battery. The headlamp automatically detects the energy source and adjusts lighting performance.

Short Description Compact, durable, and waterproof headlamp designed for proximity lighting. 350 lumens

Selling Points

- Headlamp designed for occasional professional use:
 - Durable construction: the lamp is impact resistant (IK07) and fall resistant (up to 2 meters)
 - Dustproof and waterproof (IP67)
 - Wide, uniform beam, providing comfortable lighting for close-range work
 - Three white lighting levels: MAX BURN TIME, STANDARD (better power/burn time balance), and MAX POWER
- Easy to use:
 - Single button for quick and easy lighting level selection
 - Plate allows you to easily orient the lamp in desired direction
 - Battery charge indicator shows the battery level each time lamp is turned on or off
 - LOCK function prevents the lamp from turning on during transit or storage
- Practical:
 - Adjustable headband is symmetrical to more easily adjust the fit, as well as removable and washable
 - The plate is compatible with accessories that allow you to install the headlamp on a helmet (HELMET ADAPT adhesive plate for a variety helmet types, or SLOT ADAPT for helmets that have a compatible slot)
 - ARIA 1 comes with three AAA/LR03 batteries and is also compatible with the CORE rechargeable battery (not included), with its HYBRID CONCEPT design
 - The lamp detects the energy source and optimizes lighting performance: with a rechargeable CORE battery, the lamp provides more brightness when it is turned on (450 lm in MAX POWER mode) and throughout the duration of use More information in our technical tips at Petzl.com
- Available in black with red, green, and blue lighting for stealth, and strobe to be seen

Specification

- Weight: 105g
- Brightness: 350 lumens (ANSI/PLATO FL 1)
- Beam pattern: Flood
- Watertightness: IP67
- Durability: Impact resistant IK07 (EN/IEC 62262)
- Fall resistance: 2 meters (ANSI/PLATO FL 1)
- Energy: Three AAA/LR03 batteries (included) or CORE rechargeable battery (available as accessory)
- Battery compatibility: Alkaline, lithium, or Ni-MH rechargeable
- Certification(s): CE, UKCA



Lighting performance with 3 AAA / LR03 batteries

Lighting performance as defined by the ANSI/PLATO FL 1 protocol						
Lamp Color	Lighting Color	Lighting Levels	Brightness	Distance	Burn Time	Reserve Lighting
Black, Yellow / Black	White	MAX BURN TIME	7 lm	10 m	110 h	-
		STANDARD	100 lm	45 m	12 h	20 h
		MAX POWER	350 lm	70 m	2 h	
Black	Red/Green/Blue	Continuous	4 lm	5 m	50 h	-
		Strobe	Visible at 700 m for 300 h			

Lighting performance with rechargeable CORE rechargeable battery

Lighting performance as defined by the ANSI/PLATO FL 1 protocol						
Lamp Color	Lighting Color	Lighting Levels	Brightness	Distance	Burn Time	Reserve Lighting
Black, Yellow / Black	White	MAX BURN TIME	7 lm	10 m	110 h	-
		STANDARD	100 lm	45 m	7 h	2 h
		MAX POWER	450 lm	75 m	2 h	
Black	Red/Green/Blue	Continuous	4 lm	5 m	50 h	-
		Strobe	Visible at 700 m for 300 h			

Specifications by reference

Reference(s)	E069AA00	E069BA00
		
Color(s)	Black, Yellow	Black
Guarantee	5 years	5 years
Made in	MY	MY
Inner Pack Count	1	1
Quantity Per Box	46	46
EAN	3342540840188	3342540840164

Spare part(s) Spare headband for ARIA

Accessory(ies) SHELL L
CORE
CROCHLAMP S
CROCHLAMP L
HELMET ADAPT
SLOT ADAPT
Spare headband for ARIA

Related product(s) VERTEX®
VERTEX® VENT
STRATO®
STRATO® VENT
VIZIR
VIZIR SHADOW
Protector for VERTEX® helmet
Protector for STRATO® helmet