




IP65 高温箱（带密封、无涂层）

RS 库存号 517-3507
RS 库存号 517-1409
RS 库存号 517-3462
RS 库存号 517-3484
RS 库存号 517-3478
RS 库存号 517-3434
RS 库存号 517-4459
RS 库存号 517-4465
RS 库存号 517-3440
RS 库存号 517-3456
RS 库存号 517-3490
RS 库存号 517-3529
RS 库存号 517-3428
RS 库存号 517-4421
RS 库存号 517-3513

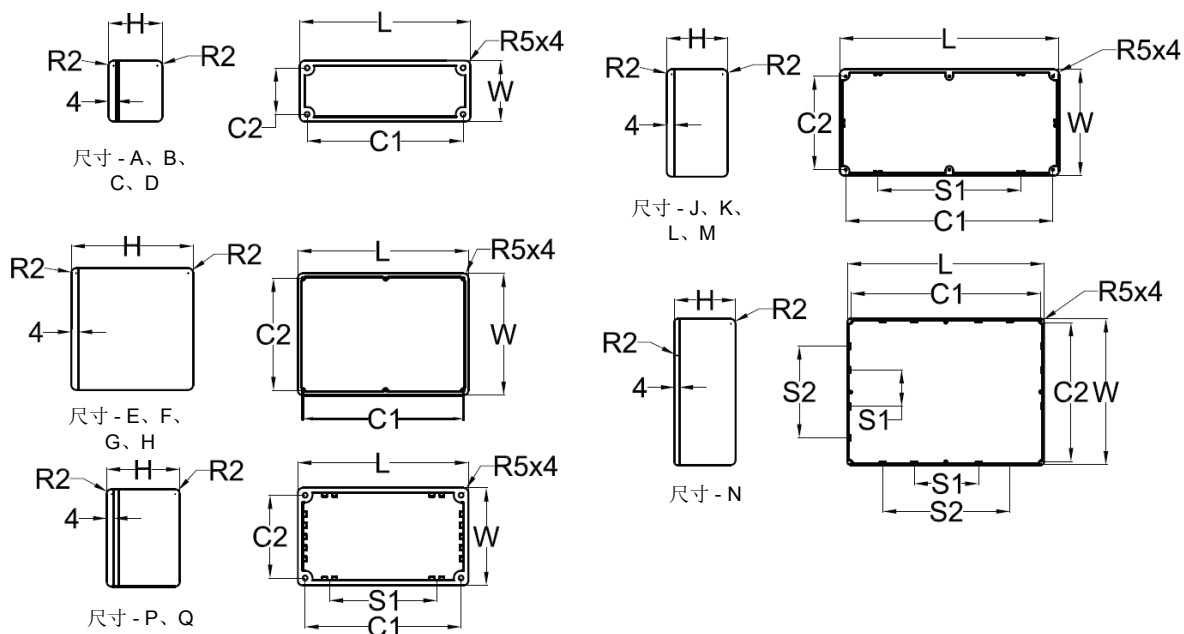

RS 库存号	尺寸号	L	W	H	C1	C2	S1	S2	壁厚
5173507	A	89.1	35.0	31.3	79.3	25.3			1.5mm
5174409	B	114.5	63.6	31.3	104.5	54.2			1.5mm
5173462	C	114.7	89.7	56.1	104.4	79.6			1.5mm
5173484	D	114.4	63.7	56.1	104.6	54.2			1.5mm
5173478	E	171.9	120.9	56.0	160.4	109.3			2mm
5173434	F	171.9	120.9	107.0	160.4	109.3			2mm
5174459	G	222.1	145.9	56.9	211.7	135.4			2mm
5174465	H	222.2	146.0	107.5	211.7	135.4			2mm
5173440	J	275.0	175.0	66.5	264.1	164.0	132.2		2mm
5173456	K	139.1	101.5	77.7	128.7	90.7	64.8		2mm
5173490	L	165.8	127.3	77.3	154.0	116.1	77.1		2mm
5173529	M	119.9	100.0	36.7	108.5	88.4	50.1		2mm
5173428	N	250.2	250.2	101.5	238.0	238.0	79.9	160.0	2.5mm
5174421	P	79.9	54.9	26.1	70.5	45.4	40.0		1.5mm
5173513	Q	60.0	54.9	31.0	50.6	45.4	30.0		1.5mm

1. 基座和盖子材料：铝合金 ADC12
2. 螺钉材料：不锈钢 M3.5x12mm Supadrive 埋头
3. 表面：纯色本色
4. 密封：3mm 厚黑色自粘式合成橡胶，氯丁橡胶，防护等级 IP65
5. 每侧盖至底座的锥形角为 1.5°