


Alphabetical Picture Part Number  
**SEARCH SEARCH SEARCH**

Go To Step Search™ Screen

**342157-1 -- 1 of 1 products**  
**Terminals and Splices**  
**Ring and Spade Tongue Terminals**

General **INFO**  
Sales **INFO**

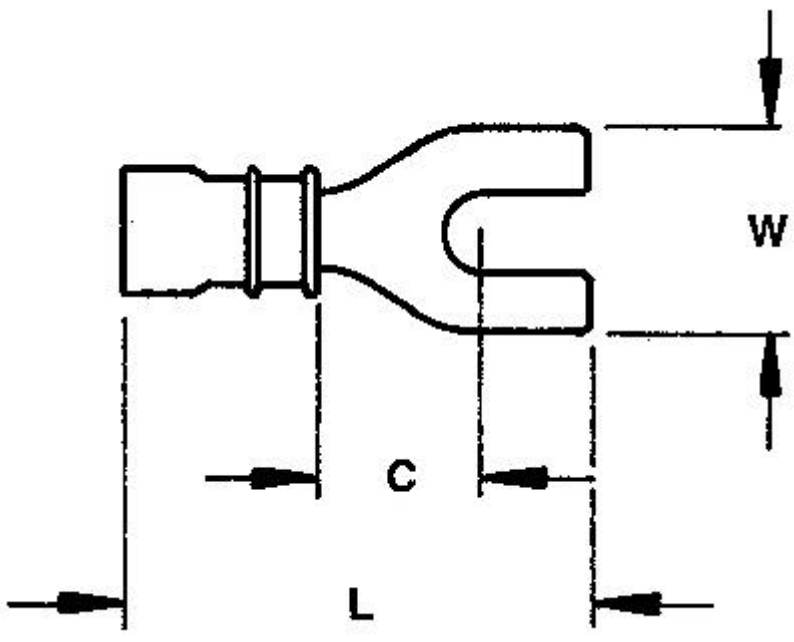

*Line art represents typical product only.*

<b><i>Searchable Features:</i></b>	
<b>Terminal Shape</b>	Spade Tongue
<b>Body Style</b>	PLASTI-GRIP
<b>Receptacle Style</b>	Straight
<b>Barrel Type</b>	Closed Barrel
<b>Wire/Cable Type</b>	Regular Wire
<b>Wire Range</b>	16-14 [1.00-2.60 <sup>2</sup> ] AWG [mm]
<b>Insulation</b>	Yes
<b>Insulation Support</b>	Non-Insulation Support
<b>Insulation Diameter</b>	.169 [4.30] Max. in. [mm]
<b>Stud Size</b>	6 [M3.5]
<b>Stud Diameter</b>	.146 [3.70] in. [mm]
<b>Shape</b>	SPADE-021
<b>Heavy Duty</b>	Standard
<b>Packaging Method</b>	Loose Piece
<b>Material</b>	Copper
<b>Finish</b>	Tin
<b><i>Other Properties:</i></b>	
<b>Dim. C</b>	.311 [7.90] in. [mm]
<b>Dim. L</b>	.890 [22.60] in. [mm]
<b>Dim. W</b>	.374 [9.50] in. [mm]
<b>Color</b>	Blue
<b>Insulation Material</b>	Vinyl
<b>Insulation Sleeve Material</b>	PVC
<b>CERTI-CRIMP Hand Tool</b>	47387-7, 525691-0 (Great Britain Tool)