



SIVACON, door, left, ventilated, IP20, H: 2000 mm, W: 400 mm, RAL 7035, protection class 1

Model		
product brand name	SIVACON	
product designation	Door	
design of the product	With ventilation openings	
design of the surface	Powder-coated	
design of the product EMC version	No	
Protection class		
protection class IP	IP20	
operating resource protection class	safety class 1	
Appearance		
RAL color number	7035	
color	light grey	
Product details		
product component		
• ventilation	Yes	
• viewing door	No	
• door for disconnecter lock	No	
Mechanical Design		
height	2 000 mm	
width	400 mm	
opening direction of the door	left	
net weight	14 kg	
material	steel	
Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens EcoTech



[Environmental Confirmations](#)

Further information

[Information on the packaging](#)

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1040-2UT15-1BA2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1040-2UT15-1BA2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8MF1040-2UT15-1BA2](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1040-2UT15-1BA2)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

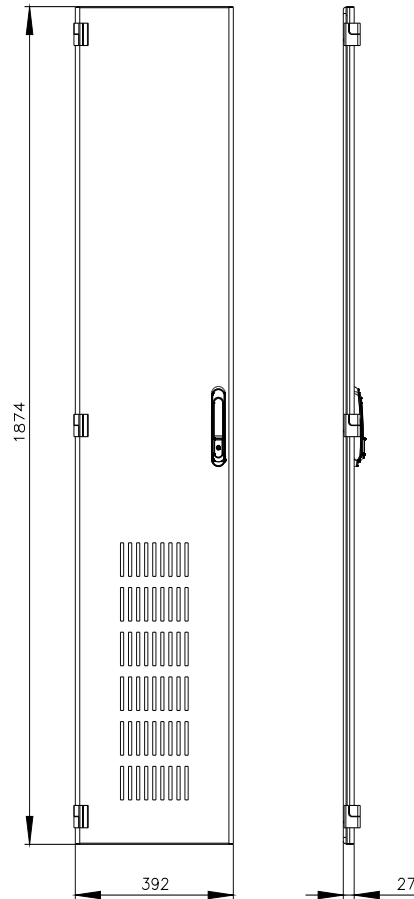

last modified:

4/13/2025 

