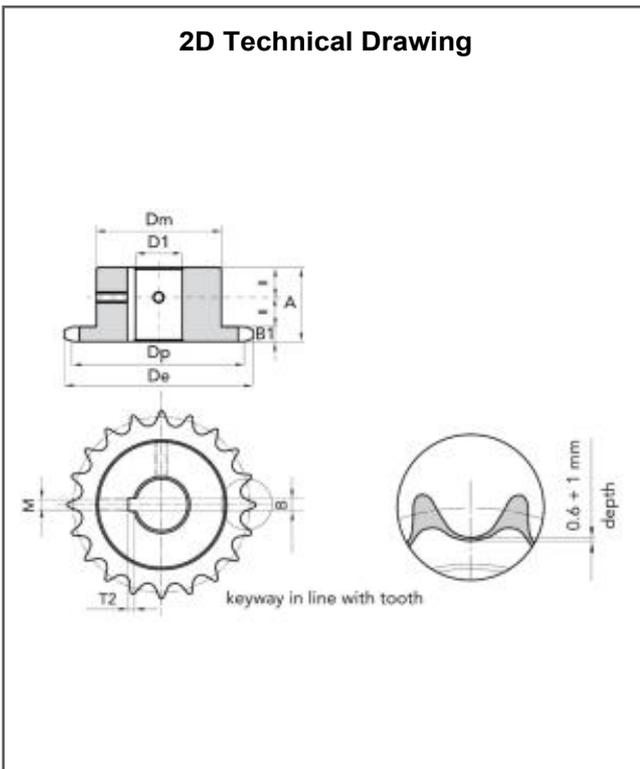


**16121625**

1/2in x 5/16in 08B-1 - THF with hole+keyway+screw holes

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

|                                       |           |
|---------------------------------------|-----------|
| Number of teeth (T)                   | 16        |
| Part number (CODE)                    | 16121625  |
| de (DE) mm                            | 69.50     |
| dp (DP) mm                            | 65.10     |
| dm (DM) mm                            | 50        |
| A (A) mm                              | 28        |
| $\varnothing D1 \text{ H7 (D1H7)}$ mm | 25        |
| B H9 (BH9) mm                         | 8.0       |
| T2 (T2) mm                            | 3.3       |
| Metric thread (M) mm                  | M6        |
| Sprockets tooth width B1 (B1) mm      | 7.2       |
| Tooth radius r3 (R3) mm               | 13.5      |
| Radius width C (C) mm                 | 1.6       |
| Material (MAT)                        | STEEL C45 |