


Fuses 5 x 20

Glass Fuses, fast-blow

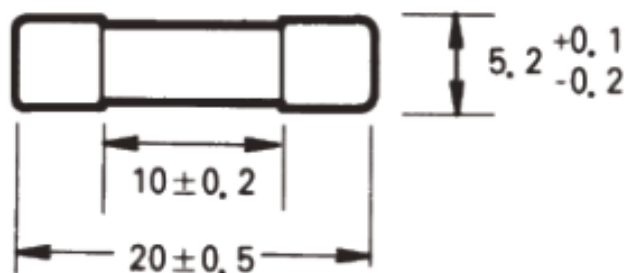

Quick blow (F) IEC60127-2/2
Nickel plated end caps

SPECIFICATION:

Characteristic (time/current)	Fast-blow
Rated voltage	250 VAC/DC
Type of housing/package/case	Glass tube
Dimensions $\varnothing \times L$	5.2 x 20 mm
Breaking capacity	35 A/ 250 V
Approvals	UL

PRODUCT RANGE:

Art. Nr.	Rated current
RND 170-00073	0.1 A
RND 170-00072	0.125 A
RND 170-00071	0.16 A
RND 170-00068	0.2 A
RND 170-00067	0.25 A
RND 170-00066	0.315 A
RND 170-00064	0.4 A
RND 170-00062	0.5 A
RND 170-00060	0.63 A
RND 170-00058	0.8 A
RND 170-00077	1 A
RND 170-00076	1.25 A
RND 170-00075	1.6 A
RND 170-00070	2 A
RND 170-00069	2.5 A
RND 170-00003	3.15 A
RND 170-00065	4 A
RND 170-00063	5 A
RND 170-00061	6.3 A
RND 170-00059	8 A
RND 170-00074	10 A