
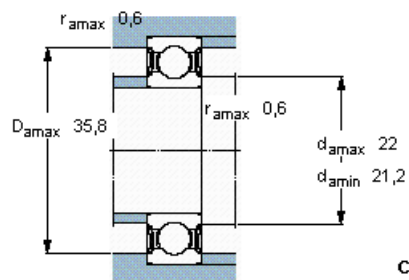


Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	40	12	9,95	4,75	0,2	-	12000	0,065	6203-2RSH *

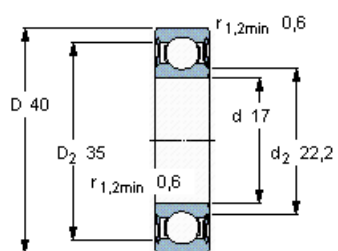

Calculation factors

$k_r = 0,025$

$f_0 = 13$