




ENGLISH

Datasheet

Stock No: 522-519

RS Pro 3 Core Screened CY Control Cable, Polyvinyl Chloride PVC Sheath

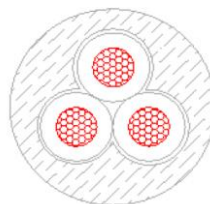

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 24$

Insulation: PVC

Insulation Dia. (mm): $2.34 \pm 0.1 \times 3C$

Tape: Mylar

Braid Shield: Tinned Copper

Conductor Dia. (mm): 0.12

Conductor Qty: 16x7

Pitch (mm):

Coverage: 70%

Jacket: PVC

Outer Dia. (mm): 7.06 ± 0.25

Colour:

The colour of the insulation: Blue ,
Brown , Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking (3 times/m):

RS 522519 CY/CC 3 Core x 0.75mm²

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
<28.1

Min. Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 6 A