



Pushbutton actuator, 1N/O, flush, green, front mount



Powering Business Worldwide™

Part no. M22-D-G-X1/K10
Article no. 216512


Catalog No. M22-D-G-X1-K10Q

Delivery programme

Product range
 Basic function
 Single unit/Complete unit
 Description
 Button plate


RMQ-Titan (drilling dimensions 22.5 mm)
 Pushbutton actuators
 Complete unit
 Flush

Function
 Contacts
 N/O = Normally open
 Contact sequence

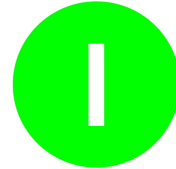

momentary

1 N/O

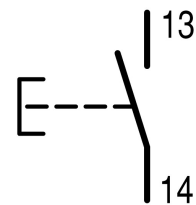

Bezel: Silver
 no

Front ring
 Connection to SmartWire-DT


Approvals

Product Standards
 UL File No.
 UL Category Control No.
 CSA File No.
 CSA Class No.
 North America Certification
 Degree of Protection

IEC/EN 60947-5; UL 508; CSA-C22.2 No. 14-05; CSA-C22.2 No. 94-91; CE marking
 E29184
 NKCR
 012528
 3211-03
 UL listed, CSA certified
 UL/CSA Type 3R, 4X, 12, 13

General

Standards
 Lifespan, mechanical
 Operating frequency
 Actuating force
 Protection type
 Climatic proofing
 Ambient temperature
 Open
 Mounting position
 Mechanical shock resistance

		IEC/EN 60947 VDE 0660
Operations	x 10 ⁶	> 1
Operations/h		 1800
	n	5
		IP67, IP69K
		Damp heat, constant, to IEC 60068-2-78 Damp heat, cyclic, to IEC 60068-2-30
	°C	
	°C	- 25 - + 70
		As required
	g	30 Shock duration 11 ms Sinusoidal according to IEC 60068-2-27

Technical data ETIM 5.0

Low-voltage industrial components (EG000017) / Push button, complete (EC001028)
 Electric engineering, automation, process control engineering / Low-voltage switch technology / Command and alarm device / Push-button actuator, complete unit
 (ecl@ss8-27-37-12-28 [AKF046010])
 Number of command positions 1
 Colour button Green
 Construction type lens Round
 Hole diameter mm 22
 Width opening mm 22
 Height meter opening mm 0
 Degree of protection (IP) IP66
 Type of button Flat

Suitable for illumination		No
Switching function latching		No
Spring-return		Yes
Supply voltage lamp	V	0
Number of contacts as normally open contact		1
Number of contacts as normally closed contact		0
Number of contacts as change-over contact		0
Type of electric connection		Screw connection
With front ring		Yes
Material front ring		Plastic
Colour front ring		Chrome

Additional product information (links)

IL04716002Z (AWA1160-1745) RMQ-Titan System	
IL04716002Z (AWA1160-1745) RMQ-Titan System	ftp://ftp.moeller.net/DOCUMENTATION/AWA_INSTRUCTIONS/IL04716002Z2013_08.pdf