

DYMO

DYMO® Industrial Labels

Label it fast, label it once, label it right.



This product guide contains RS Stock Numbers

Tough, jobsite-tested labels for industrial applications.

Rely on DYMO® Industrial Labels.

DYMO® Industrial labels are tough – jobsite tested and UL recognized.

Thermal transfer printing means labels won't smudge, smear or fade.

Choose up to a 24 mm label width in a broad assortment of materials and colours that meet OSHA, ANSI, and ISO standards.

All DYMO® Industrial labels are distributed from an easy-to-load cartridge, and with a split-back design, peeling and applying is quick and easy.

DYMO® Industrial labels help you get labelling jobs done fast, and done right – the first time.



DYMO® Industrial Labels are available in:

Flexible Nylon
Permanent Polyester
Indoor/Outdoor Vinyl
Heat-Shrink Tube
Non-Adhesive Tag
Self-Laminating




Labels



DYMO® Industrial Label Benefits:

- 1 Industrial-strength adhesives resist moisture, extreme temperatures, UV light and more – so labels won't curl or fall off
- 2 Available in a range of UL recognized materials for virtually every industrial labelling application; heat-shrink tubes tested to SAE, ASTM and military specifications
- 3 Thermal transfer printing technology – label text won't smudge, smear, or fade
- 4 Choose from 6, 9, 12, 19, and 24 mm label widths in a broad colour assortment that meet OSHA, ANSI, and ISO standards
- 5 Easy-to-peel split back design makes applying labels quick and easy

The right label for virtually every situation and surface.

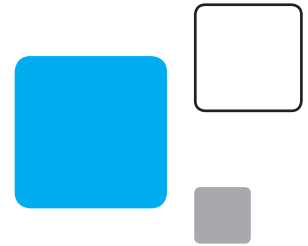

Indoor/Outdoor Vinyl

For general labelling or extreme conditions. Vinyl labels offer moisture, chemical and UV resistance, making them ideal for labelling both indoors and outdoors. Available in the widest range of colours that adhere to OSHA, ANSI and ISO colour standards.

UL recognized as a component to UL 969

Flexible Nylon

For labelling wires, cables and rounded surfaces. Flexible Nylon labels conform and stick tightly to wires, cables, curved and textured surfaces. Tear-proof material resists damage when pulled through tight spaces or conduits.

UL recognized as a component to UL 969

Permanent Polyester

For labelling panels, blocks, faceplates, shelves, bins, beams and more. Permanent Polyester labels have a polished finish that leaves your work looking professional. Available in smaller widths that fit most patch panels, blocks and other distribution panels.

UL recognized as a component to UL 969

Heat-Shrink Tube

For high-end cable identification. A 3:1 shrink ratio helps ensure a secure fit on wires and cables. Print directly on Heat-Shrink Tubes with any DYMO® Industrial labelling tool.

Meets MIL-M-81531, MIL-STD-202G, SAE-DTL- 23053/5 (Class 1 & 3)
UL recognized as a component to UL 224

Non-Adhesive Tag

For sliding into racks or faceplates that do not require adhesive. Made from polyester for increased durability.











Self-Laminating

Self-Laminating labels protect your printed area from exposure to oil, solvents, water and abrasion when applied to wires and cables.

All DYMO® Industrial labels are RoHS compliant.

For technical specifications on all DYMO® Industrial label types, please visit our website at:
www.dymo.com/industrial

How to choose the right DYMO® Industrial label:

ENVIRONMENT							
SURFACE		Heat/Cold Resistant	UV Light Resistant	Oil Resistant	Water Resistant	Chemical Resistant	Colour Coding
 Cable/Wire	Flexible Nylon Heat-Shrink Tube	Indoor/Outdoor Vinyl Heat-Shrink Tube	Indoor/Outdoor Vinyl Heat-Shrink Tube	Indoor/Outdoor Vinyl Heat-Shrink Tube	Indoor/Outdoor Vinyl Heat-Shrink Tube	Indoor/Outdoor Vinyl Heat-Shrink Tube	Indoor/Outdoor Vinyl
 Curved Surface	Flexible Nylon Indoor/Outdoor Vinyl	Indoor/Outdoor Vinyl Flexible Nylon	Indoor/Outdoor Vinyl	Indoor/Outdoor Vinyl Flexible Nylon	Indoor/Outdoor Vinyl	Indoor/Outdoor Vinyl	Indoor/Outdoor Vinyl
 Flat Surface	Permanent Polyester Flexible Nylon	Permanent Polyester Indoor/Outdoor Vinyl	Permanent Polyester Indoor/Outdoor Vinyl	Permanent Polyester Indoor/Outdoor Vinyl	Permanent Polyester Indoor/Outdoor Vinyl	Permanent Polyester Indoor/Outdoor Vinyl	Indoor/Outdoor Vinyl
 Textured Surface	Permanent Polyester Flexible Nylon	Indoor/Outdoor Vinyl Permanent Polyester	Indoor/Outdoor Vinyl Permanent Polyester	Indoor/Outdoor Vinyl Permanent Polyester	Indoor/Outdoor Vinyl Permanent Polyester	Indoor/Outdoor Vinyl Permanent Polyester	Indoor/Outdoor Vinyl

Top = Best Option Bottom = Alternate Option

Available DYMO® Industrial label widths and colours:



IND	LABEL APPLICATIONS	LABEL COLOUR	Width				
			6 mm	9 mm	12 mm	19 mm	24 mm
Labels that stick and stay stuck. DYMO® Industrial labels are tough— jobsite tested and UL recognized. Labels won't smear or fade and are built with industrial-strength adhesives to resist moisture, UV light and extreme temperatures. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO® Industrial labels have you covered. DYMO® Industrial labels are designed to work exclusively with Rhino™ printers and to perform on a variety of surfaces. LEARN MORE: www.dymo.com/industrial	BLACK ON WHITE – 4780277 4780283 4780299 7457759	BLACK ON WHITE	–	4780277	4780283	4780299	7457759
		BLACK ON YELLOW	–	–	4780148	4780160	7457740
		BLACK ON ORANGE	–	–	4780182	4780198	7457743
		BLACK ON GREY	–	–	7457706	7457721	7457753
		WHITE ON RED	–	–	7457692	7457719	7457747
		WHITE ON BLACK	–	7457699	7457715	7457731	7457778
		WHITE ON GREEN	–	–	7457696	7457728	7457756
VINYL - UL Recognized Component to UL969 - RoHS compliant Length 5.5 m 	WHITE ON BLUE	–	–	7457709	7457725	7457762	
	WHITE ON PURPLE	–	–	7457703	7457734	7457765	
	WHITE ON BROWN	–	–	7457712	7457737	7457769	
PERMANENT POLYESTER - UL Recognized Component to UL969 - RoHS compliant Length 5.5 m 	BLACK ON WHITE	7457668	4780069	4780075	4780081	522282	
	BLACK ON CLEAR	7457670	4780306	7457674	7457683	7457680	
	BLACK ON METALLIC	7457677	4780104	4780110	4780126	7457686	
HEAT SHRINK TUBES - UL Recognized Component to UL224 - Meets MIL-STD-202G, MIL-M-81531 & SAE-DTL 23053/5 (Class 1 & 3) - RoHS compliant Length 1.5 m 	BLACK ON WHITE	5156760	7335883	5155565	5156782	7951356	
	BLACK ON YELLOW	5156798	5156805	5156827	5156833	7951365	
FLEXIBLE NYLON - UL Recognized Component to UL969 - RoHS compliant Length 3.5 m 	BLACK ON WHITE	–	–	4780025	4780031	522294	
	BLACK ON YELLOW	–	–	4780047	4780053	522272	
NON-ADHESIVE TAG - RoHS compliant Length 5.5 m 	BLACK ON WHITE	18111	–	18113	–	–	
SELF-LAMINATING - RoHS compliant Length 5.5 m 	BLACK ON WHITE	–	–	–	–	522298	

For more information or to find out your nearest distributor, please visit www.dymo.com/industrial or call us at +44 (0) 20 7341 5529.



©2018 Newell Brands
 Newell Europe Sàrl
 Chemin de Blandonnet 10
 1214 Vernier - Switzerland