


# 21 91 02

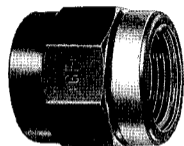


## Übergangs-Muffen, PVC-U

mit mm-Klebemuffe und zylindrischem Rohr-Innengewinde Rp  
Verstärkungsring rostfrei A2

Anschluss für Kunststoff- oder Metallgewinde

Keine PVC-schädigenden Gewindedichtpasten verwenden

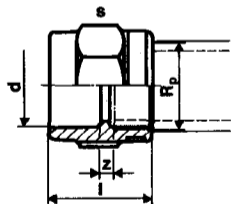**A**

d - Rp	PN	Bestell-Nr.		SP	GP	g	z	l	s					
12- 1/4"	16	<b>721 910 204</b>		10	400	10	4	27	22					
16- 3/8"	16	<b>721 910 205</b>		10	280	16	5	31	27					
20- 1/2"	16	<b>721 910 206</b>		10	150	25	5	35,5	32					
25- 3/4"	16	<b>721 910 207</b>		10	100	33	5	40	36					
32-1"	16	<b>721 910 208</b>		5	50	56	5	45	46					
40-1 1/4"	16	<b>721 910 209</b>		10	100	100	5	51	55					
50-1 1/2"	16	<b>721 910 210</b>		10	60	125	7	59	65					
63-2"	16	<b>721 910 211</b>		5	50	170	7	69	80					