

# Indicator

17-040352

Distribution by  
Rs-online<https://rs-online.eao.com/p/17-040352>

Your product:

---



## 17-040352 Indicator

### FRONT

|                  |                                        |
|------------------|----------------------------------------|
| Front dimension: | Ø 9,5 mm                               |
| Front form:      | Round                                  |
| Reflector:       | Metal, polished chromium-plated, domed |

### MOUNTING

|                   |                |
|-------------------|----------------|
| Design:           | Raised         |
| Mounting cut-out: | Ø 8 mm         |
| Mounting type:    | Panel mounting |

### OPERATING-/INDICATION PART

|                      |        |
|----------------------|--------|
| Illumination colour: | Yellow |
|----------------------|--------|

### ELECTRICAL CHARACTERISTICS

|                    |                                                                                 |
|--------------------|---------------------------------------------------------------------------------|
| Operating voltage: | 24 V DC                                                                         |
| Operation current: | 20 mA ±15 %                                                                     |
| Lumi. Intensity:   | 32 mcd                                                                          |
| Polarity:          | Anode (+) Brass plug-in connector<br>Cathode (-) Brass tinned plug-in connector |

### MECHANICAL CHARATERISTIC

|                           |                                |
|---------------------------|--------------------------------|
| <b>Terminal:</b>          | Plug-in terminal, 2.8 x 0.8 mm |
| <b>Tightening torque:</b> | Fixing nut max. 0.2 Nm         |
| <b>Weight:</b>            | 0.005 kg                       |

## AMBIENT CONDITION

|                               |                                                          |
|-------------------------------|----------------------------------------------------------|
| <b>IP Protection:</b>         | IP40 front side, IP65 front side, according to IEC 60529 |
| <b>Operating temperature:</b> | – 20 °C ... + 60 °C                                      |
| <b>Storage temperature:</b>   | – 25 °C ... + 80 °C                                      |

## CERTIFICATE

|                      |                                                 |
|----------------------|-------------------------------------------------|
| <b>Approbations:</b> | UL                                              |
| <b>Conformities:</b> | 2011 / 65 / EC (RoHS), 2014 / 35 / EU (230 VAC) |
| <b>REACH:</b>        | REACH compliant                                 |
| <b>RoHS:</b>         | RoHS compliant                                  |


## OTHER

**Short Description:** Indicator, Ø 8 mm, Ø 9,5 mm, Round, Plug-in terminal, 2.8 x 0.8 mm, Yellow


**Kind of illumination:** Single-LED

**Hints:** Connectors: Brass terminal = anode (+); brass tinned terminal = cathode (-), IP67 front side gap between LED and reflector and gap between reflector and frontplate sealed to IP67 when using the supplied gasket., The plastic is limited resistant to chemicals.


**Wiring diagrams:**

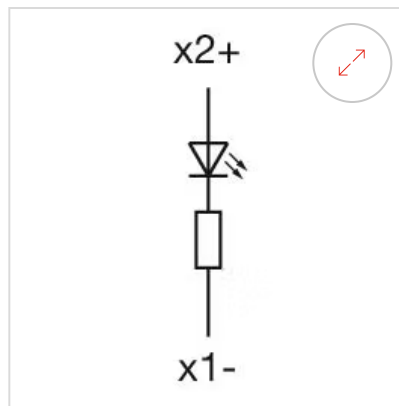

**Mounting cut-outs:**

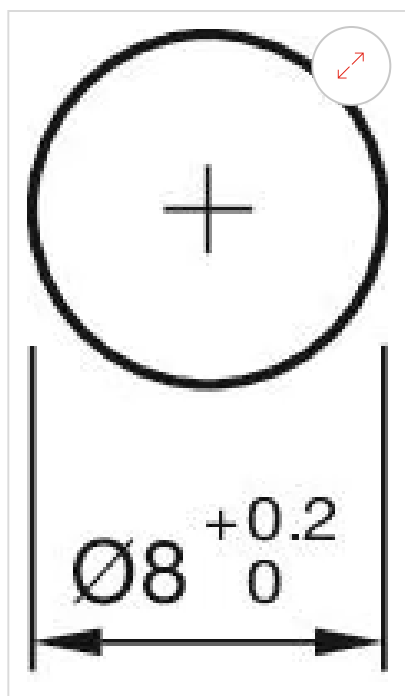

**Dimension drawings:**

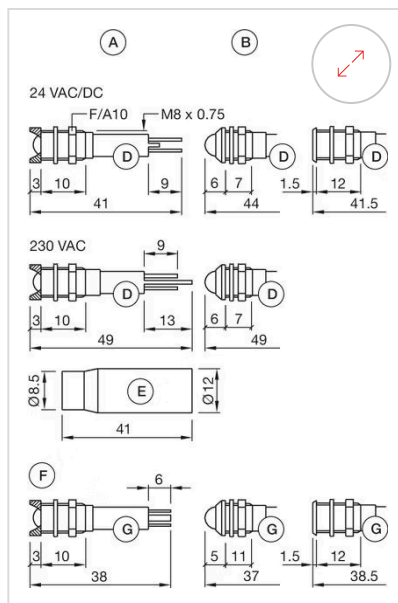

- A = interior
- B = exterior
- C = superflat
- D = Plug-in terminal 2.8 mm x 0.8 mm
- E = Multi-colour
- F = Protection tube
- G = Plug-in terminal 2.0 mm x 0.5 mm