


datasheet for AK 2 B 2540 I
 article number: 972405100

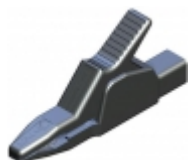

product description:	order number: 972 405-100
description:	Contact-protected, high strength, wide-opening alligator clip. Clamping range up to a bolt diameter of 30 mm. Solid wire clip, U-shaped, fine wire face; 4 mm diameter brass connecting socket, suitable for use with safety-type measuring leads.
typ:	AK 2 B 2540 I schwarz/black
system:	4 mm safety system
order number:	972 405-100
clamping range:	30 mm
color	●
other color versions:	●●●●●
technical data	
measurement category	CAT II
norm	DIN EN 61010-031
type of contact:	to clamp
type of termination:	4 mm socket, unsprung
rated voltage:	AC/DC 1000 V
rated current:	32 A
contact resistance:	10 mOhm
material	
contact material:	brass
contact surface material:	nickel
housing material:	PP
environmental conditions:	
temperature range:	-30 °C to +90 °C
inflammable class:	
housing:	94 HB
drawing	

