


Premium-Line FB Extension Lead with Safety Fuse Reset Button and USB-Charger 2100 mA 5-way 3 m H05VV-F3G1.5 black *GB*

Extra H/D cable 3G1.5 mm² for high product safety.

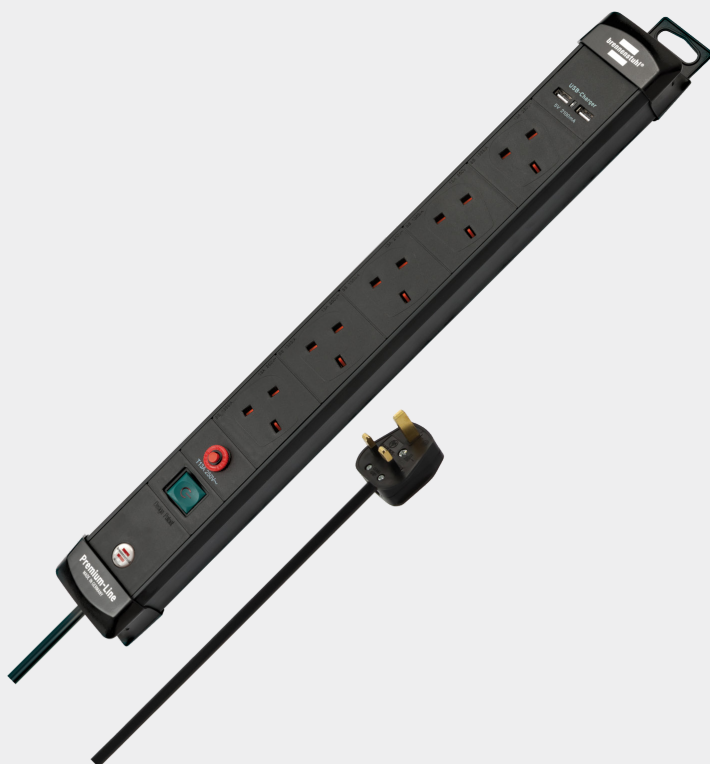

MADE IN GERMANY

5 YEARS
MANUFACTURER
GUARANTEE



Product number
EAN

1951153600
4007123648542

DESCRIPTION

- Advanced „fuse button reset function“ eliminates time consuming plug fuse replacement. Simply resettable in case of overload.
- Robust extension lead, designed to be the best and made of break-resistant special plastic material.
- Elegant, sleek, timeless, high-quality design.
- Earthed sockets in a 45° arrangement, ideal for angular plugs.
- 2 USB-charging units 2100 mA.
- Illuminated 2-pole ON/OFF safety switch.
- With option to wind the cable around the rail for storage.
- With practical hanging facility.
- Innovative and individual fixture system.
- Sockets with increased touch protection.
- Packaging: Shrink-wrapped - for protection against dust and contamination.

TECHNICAL DATA

Cable quality	PVC	Circuit breaker	No
Cable length	3 m	Max. current carrying capacity	13 A
Cable designation	H05VV-F 3G1,5	USB charging units	2x / Technische Attribute/Anschlussbuchse/Typ A
Socket outlets total	5	Max. output current USB	2.1 A
Plug system plug	Type G (GB)	Output socket type A	2
Socket outlets switchable	1x 5	Colour	black

PACKAGING, DIMENSIONS AND WEIGHTS

UP	4	Weight of product (including packaging)	0.93 kg
Weight of product (without packaging)	0.91 kg	Dimension LxWxH (incl. packing)	7 cm x 10 cm x 60 cm
Dimension LxWxH (without packing)	6.7 cm x 9 cm x 60 cm		