

## FEATURES

- Light, sturdy, and transportable for top-level performance.
- Maximum Durability thanks to specific anti-corrosion treatment, protective against the atmospheric agents
- Double stage for a very low effort on the lever and an increased efficiency
- Significant reduction of fatigue during operations
- Compact and sturdy construction for heavy duty
- Lightweight and compact
- Single acting cylinder compatibility
- Compact and sturdy construction for heavy duty
- Foot Pedal for easy operation
- Made in Italy

## RS PRO Portable Hydraulic Pump with Foot Pedal

RS Stock No.: 0309328



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


## Product Description


This RS PRO Hydraulic Hand Pump is light, sturdy, and transportable for top-level performance and max durability thanks to specific anti-corrosion treatments, protective against the atmospheric agents.

- This is foot pedal operated pump.
- Double stage for a very low effort on the pedal and an increased efficiency
- Significant reduction of fatigue during operations
- Steel construction for maximum strength and durability
- Lightweight and compact
- Single acting cylinder compatibility
- Compact and sturdy construction for heavy duty
- It does not require any pneumatic network, compressors, or any other devices for operation.
- Easy to handle and transport.
- Versatile use in both horizontal & vertical positions
- Maximum Operating pressure 700 bar
- Externally adjustable safety valves to protect against overloads.
- Slide with slots for perfect stability and easy installation onto the application.
- Light weight and overall dimensions.
- Made in Italy

## Specifications

<b>Maximum Operating Pressure</b>	700 bar
<b>Single/Two Speed</b>	Double
<b>Usable Oil Capacity</b>	1.4 l
<b>Oil Port</b>	3/8" NPT
<b>Cylinder Stroke</b>	24 mm
<b>Displacement per Stroke 1st Stage</b>	11.8 cm <sup>3</sup>
<b>Displacement per Stroke 2nd Stage</b>	1.9 cm <sup>3</sup>
<b>Max Force</b>	43 kg
<b>Dimensions</b>	598 x 182 x 193 mm
<b>Weight</b>	8.55 kg
<b>Height</b>	193 mm
<b>Width</b>	182 mm
<b>Length</b>	598 mm
<b>Dimensions (Packed product)</b>	640 x 190 x 200 mm
<b>Outlet Type</b>	NPT 3/8"
<b>Handle / Pedal Operated</b>	Pedal

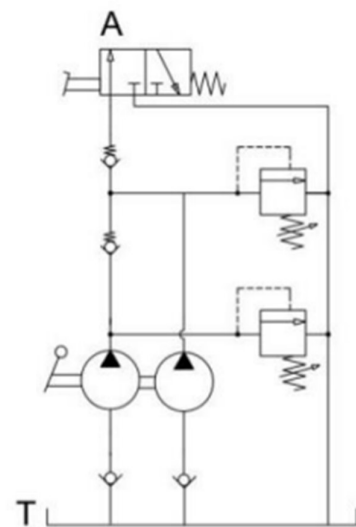

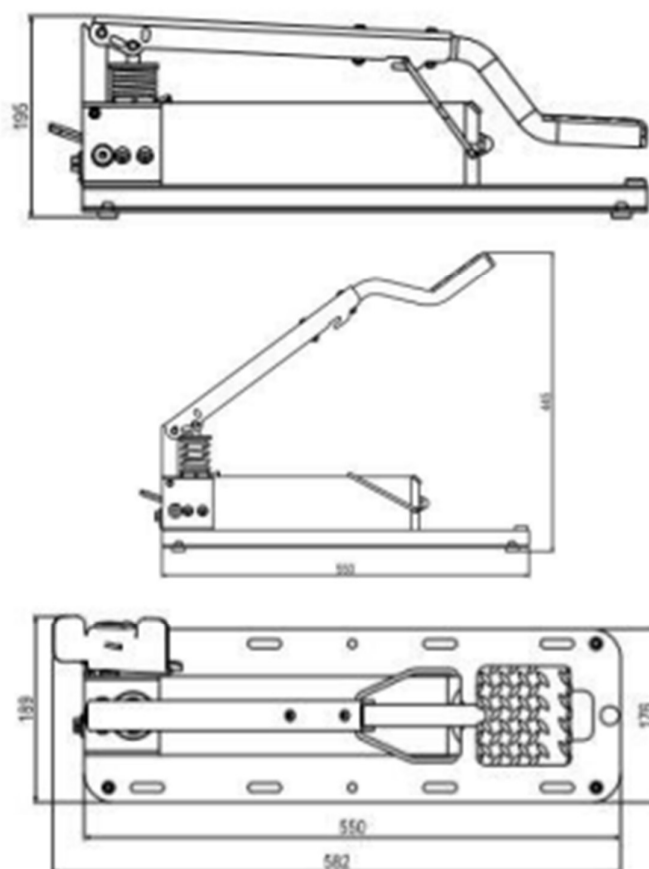**Drawings****Additional Information**

Please note this is individual pump, no accessories included.

Please review our RS PRO Hydraulic Hand Pump Guide to see whole Range & Accessories available.

## Hydraulic Foot Pump

