


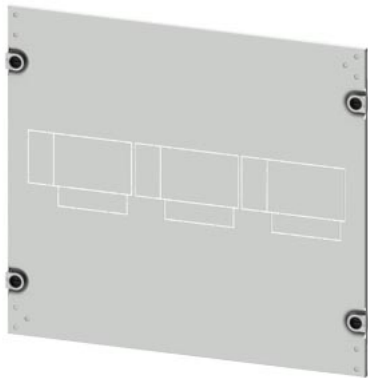

Masking frame 3VA20 (100 A), 3VA21 (160 A), 3VA22 (250 A), 3 or 4-pole, fixed-mounted, plug-in design, 8US setup, drive: direct, front-mounted rotary operator, RCD: without, H: 450 mm W: 600 mm

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	2.3 kg
height	450 mm
width	600 mm
depth	10 mm
installation width for cabinet installation	600 mm
mounting height for device equipment can be used	450 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other



[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2045-6BA11>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2045-6BA11>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2045-6BA11
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

